

# N-F BULKHEAD CRIMP RG174, RG316

SC9331

## SPECIFICATIONS

### ELECTRICAL:

FREQUENCY: 0-11 GHZ  
 VSWR 1.3:1 MAX  
 IMPEDANCE: 50 OHMS



 
### MECHANICAL:

MATERIAL BODY: Ni PLATED BRASS  
 CENTER CONTACT: BeCu  
 CONTACT PLATING: Au MIL-G-45204  
 DIELECTRIC: PTFE  
 INTERFACE: MIL-STD-348B  
 CAPTIVE CONTACT  
 ROHS COMPLIANT  
 OP. TEMP RANGE: -55°C- +155°C


CABLES: RG174, RG316

### ASSEMBLY:

TRIM CABLE AS SHOWN;  
 SLIDE ON CRIMP SLEEVE,  
 SOLDER CONTACT ON CONDUCTOR,  
 FLIUSH WITH DIELECTRIC;  
 INSERT CABLE INTO BODY UNTIL IT SNAPS;  
 CRIMP

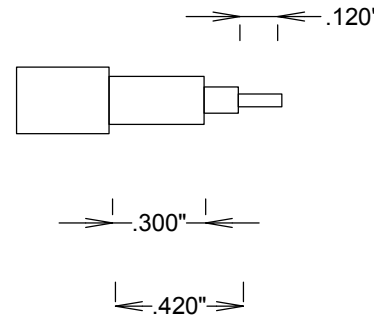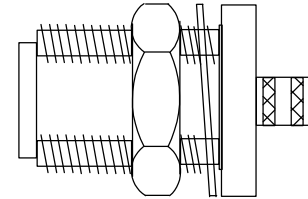

STRIPPING DIMENSIONS

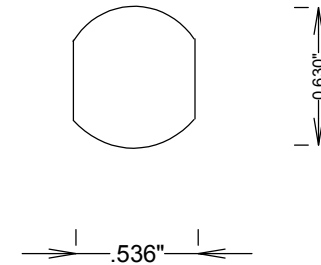

RECOMMENDED CUTOUT

				<b>FAIRVIEW MICROWAVE INC.</b>	
				ALLEN, TX 75013 <a href="http://WWW.FAIRVIEWMICROWAVE.COM">WWW.FAIRVIEWMICROWAVE.COM</a>	
				TITLE	
				N-F BULKHEAD CRIMP RG174, RG316	
SIZE		CAGE CODE	DWG NO	REV	
<b>A</b>		3FKR5	<b>SC9331</b>	--	
SCALE			SHEET		