

TNC INNER DC BLOCK

SD3455


SPECIFICATIONS

ELECTRICAL


FREQUENCY: 0.01-3 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.25:1 MAX
 INSERTION LOSS: 0.2DB MAX @2GHZ;
 0.35DB MAX@3GHZ
 200 VOLTS

MECHANICAL

MATERIALS BODY: NICKEL PLATED BRASS

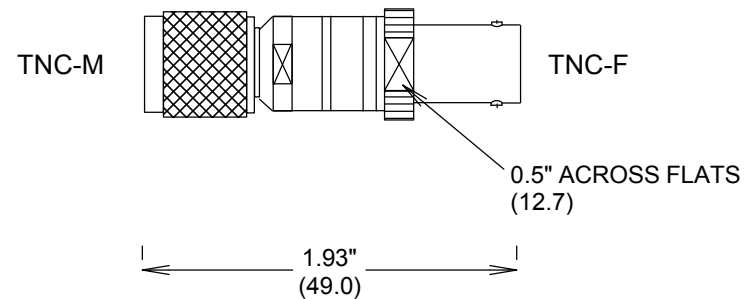

MEASUREMENTS BELOW ARE TYPICAL

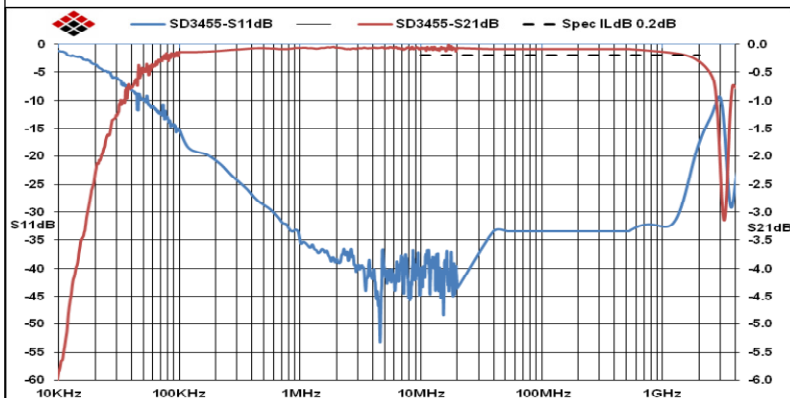

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

TNC INNER DC BLOCK

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SD3455	A
SCALE	SHEET		