

## .141 Semi-rigid Formable Coax Cable Black FEP Jacket

Formable semi-rigid coax is a hand formable version of standard semi-rigid that does not require complicated and costly preformed cable assemblies. Because the dimensions and electrical characteristics are so closely matched to semi-rigid coax, standard semi-rigid connectors can be used. The tin soaked copper braid outer shield provides excellent RF shielding. FEP Jacket reduces the chance of shorting exposed contacts or circuit conductors.

### Electrical Specifications

| Description             | Min | Typ           | Max   | Units           |
|-------------------------|-----|---------------|-------|-----------------|
| Frequency Range         | DC  |               | 20    | GHz             |
| Cutoff Frequency        |     | 34            |       | GHz             |
| Impedance               |     | 50            |       | Ohms            |
| Velocity of Propagation |     | 70            |       | %               |
| Time Delay              |     | 1.43 [4.69]   |       | ns/ft [ns/m]    |
| Shielding Effectiveness | 110 |               |       | dB              |
| Operating Voltage (AC)  |     |               | 1,900 | Vrms            |
| Nominal Capacitance     |     | 29<br>[95.14] |       | pF/ft<br>[pF/m] |

### Performance by Frequency Band

| Description      | F1         | F2          | F3          | F4           | F5           | Units               |
|------------------|------------|-------------|-------------|--------------|--------------|---------------------|
| Frequency        | 0.5        | 1           | 5           | 10           | 20           | GHz                 |
| Attenuation, Typ | 8<br>26.25 | 12<br>39.37 | 29<br>95.14 | 45<br>147.64 | 70<br>229.66 | dB/100ft<br>dB/100m |

### Mechanical Specifications

|                                 |                          |
|---------------------------------|--------------------------|
| Diameter                        | 0.161 in [4.09 mm]       |
| Weight                          | 0.029 lbs/ft [0.04 kg/m] |
| Min. Bend Radius (Installation) | 0.315 in [8 mm]          |
| Min. Bend Radius (Repeated)     | 1.575 in [40.01 mm]      |

### Construction Specifications

| Description     | Material and Plating                 | Diameter           |
|-----------------|--------------------------------------|--------------------|
| Inner Conductor | Copper Clad Steel, Silver, 1 Strands | 0.036 in [0.91 mm] |
| Conductor Type  | Solid                                |                    |
| Dielectric      | PTFE                                 | 0.117 in [2.97 mm] |
| First Shield    | Tinned Copper Braid                  | [ ]                |
| Jacket          | FEP, Black                           | 0.161 in [4.09 mm] |



### Configuration:

- Formable Cable
- 1 Shield(s)

### Features:

- Dimensionally the same as standard solid outer conductor semi-rigid coax
- Standard semi-rigid connectors can be used
- Cable is hand formable and does not require special tools to bend
- Connectors are easily soldered to Tin soaked outer conductor
- Cable can be formed more than once without damage to outer conductor
- High RF Shielding >100 dB

Fairview Microwave  
 301 Leora Ln., Suite 100  
 Lewisville, TX 75056  
 Tel: 1-800-715-4396 / (972) 649-6678  
 Fax: (972) 649-6689  
[www.fairviewmicrowave.com](http://www.fairviewmicrowave.com)  
[sales@fairviewmicrowave.com](mailto:sales@fairviewmicrowave.com)

## Environmental Specifications

### Temperature

Operating Range -65 to +150 deg C

**Compliance Certifications** (see [product page](#) for current document)

## Plotted and Other Data

Notes:


.141 Semi-rigid Formable Coax Cable Black FEP Jacket from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and millimeter wave products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [.141 Semi-rigid Formable Coax Cable Black FEP Jacket FM-SR141TBJ-BULK](#)

URL: <https://www.fairviewmicrowave.com/fm-sr141tbj-formable-coax-cable-fep-jacket-fm-sr141tbj-bulk-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

| REVISIONS |                 |            |          |
|-----------|-----------------|------------|----------|
| REV.      | DESCRIPTION     | DATE       | APPROVED |
| A         | INITIAL RELEASE | 03/24/2022 | AGANWANI |

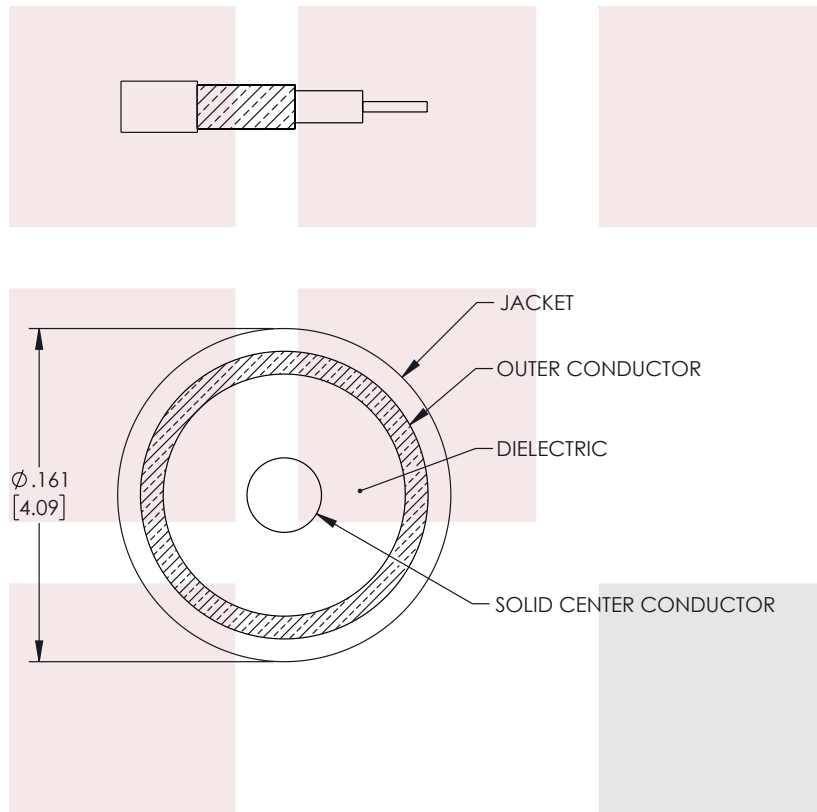

THESE COMMODITIES, TECHNOLOGY OR SOFTWARE WERE EXPORTED FROM THE UNITED STATES IN ACCORDANCE WITH THE EXPORT ADMINISTRATION REGULATIONS. DIVERSION CONTRARY TO U.S. LAW PROHIBITED.

|   |   |   |   |     |
|---|---|---|---|-----|
| <p><b>Fairview Microwave</b><br/>an INFINIT<sup>®</sup> brand</p> | UNLESS OTHERWISE SPECIFIED LEADING DIMENSIONS ARE INCHES<br>DIMENSIONS IN [ ] ARE MILLIMETERS |   | THIRD-ANGLE PROJECTION<br>  |     |
|   | TOLERANCES:   |   | CABLE LENGTH (L) TOLERANCES:  |     |
| TITLE   | .X = ±.2 [5.08] FRACTIONS   | L ≤ 12 [305] = +1 [25] / -0                 | THE INFORMATION AND DESIGN IN THIS DOCUMENT IS THE PROPERTY OF FAIRVIEW MICROWAVE CORPORATION. ALL RIGHTS RESERVED.<br>SHEET 1 OF 1 |     |
| .141 Semi-rigid Formable Coax Cable Black FEP Jacket              | .XX = ±.02 [.51] ± 1/32   | 12 [305] < L ≤ 60 [1524] = +2 [51] / -0     |   |     |
|   | .XXX = ±.005 [.13] ANGLES ± 1°  | 60 [1524] < L ≤ 120 [3048] = +4 [102] / -0  | SCALE N/A   |     |
|   |   | 120 [3048] < L ≤ 300 [7620] = +6 [152] / -0 |   |     |
|   |   | 300 [7620] < L = +5%L / -0                  |   |     |
| ALL DIMENSIONS SHOWN ARE FOR REFERENCE ONLY.                      |   |   |   |     |
| SIZE  | CAGE CODE   | DRAWN BY                                    | ITEM NO.  | REV |
| A   | 3FKR5   | DZINN                                       | FM-SR141TBJ-BULK  | A   |

T-Rev.D