

**10 dB Fixed Attenuator 4.3-10 Male To
 4.3-10 Female Up To 6 GHz Rated To 15 Watts**

Fairview Microwave carries a broad selection of fixed attenuators with a wide range of attenuation levels, frequency ranges, and power dissipation ranges. Also known as RF pads, RF microwave attenuators lower the amplitude of a signal (or attenuate) a known amount. These attenuator pads can be used in a wide variety of applications including reducing a signal level to protect measurement equipment or other circuitry, extending the range of power meters and amplifiers, and impedance matching circuits by reducing the VSWR seen by adjacent components. RF attenuators can prevent signal overload in amplifiers, receivers and detectors, adjusting the signal level to a range that is optimal.

Few RF components are as commonly used as fixed coaxial attenuators, and Fairview Microwave carries one of the largest in-stock varieties and ships them same day. The FMAP1001-10 is a 10 dB Fixed Attenuator that operates from DC to 6 GHz and is rated to 15 Watts. The versatile coaxial package uses 4.3-10 male to 4.3-10 female connectors and is also REACH and RoHS compliant.



Features:

- Bidirectional
- DC to 6 GHz Frequency Range
- Attenuation 10 ±0.3 dB
- Max Power 15 Watts (CW)
- VSWR < 1.15:1

Applications:

- Instrumentation
- Precision measurements
- Prototyping and characterization
- Production systems

Electrical Specifications

Description	Min	Typ	Max	Units
Frequency Range	DC		6	GHz
Impedance		50		Ohms
Nominal Attenuation		10		dB
VSWR			1.15:1	
Input Power, CW			15	Watts
Input Power, Peak 1 μs, 1%			250	Watts

Mechanical Specifications

Size	
Weight	0.237 lbs [107.5 g]
Configuration	
Design	Fixed

Connectors

Description	Connector 1	Connector 2
Type	4.3-10 Male	4.3-10 Female

Environmental Specifications

Temperature	
Operating Range	-40 to +85 deg C



Compliance Certifications (see [product page](#) for current document)


Plotted and Other Data

Notes:

Fairview Microwave
 301 Leora Ln., Suite 100
 Lewisville, TX 75056
 Tel: 1-800-715-4396 / (972) 649-6678
 Fax: (972) 649-6689
www.fairviewmicrowave.com
sales@fairviewmicrowave.com

Typical Performance Data

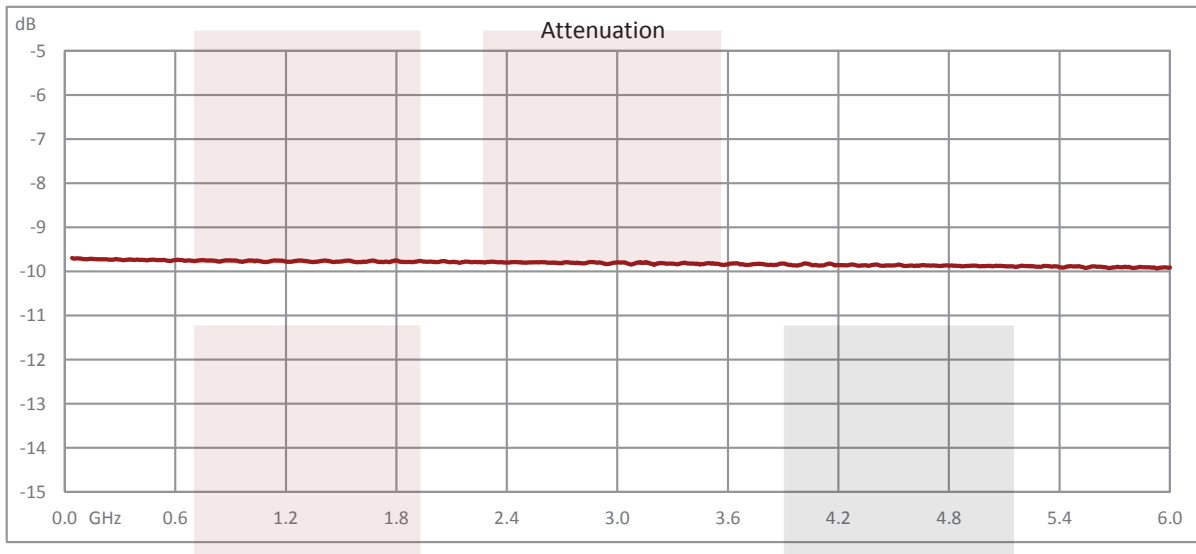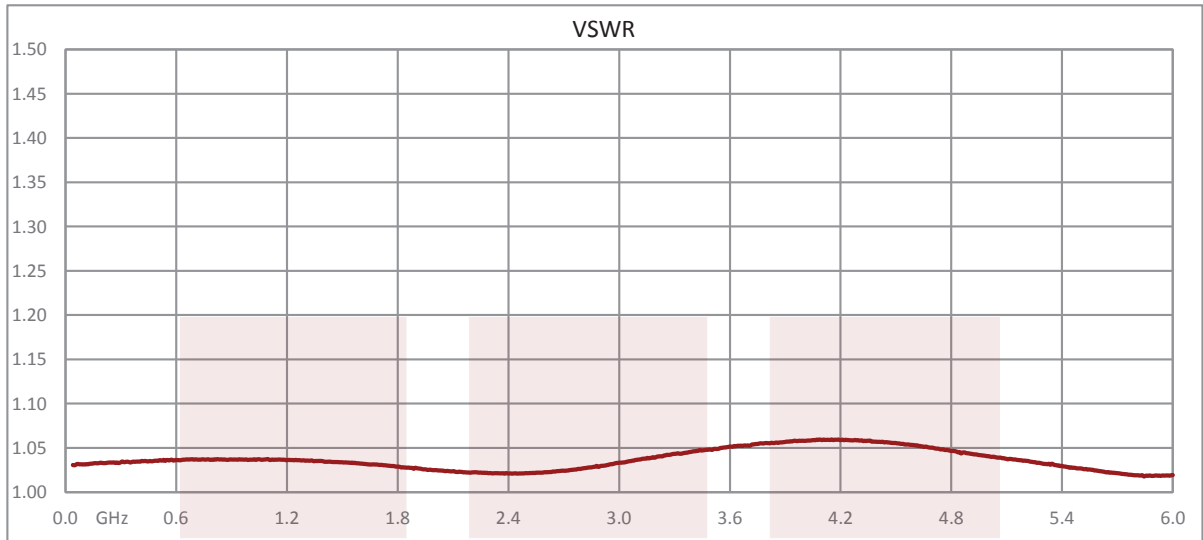

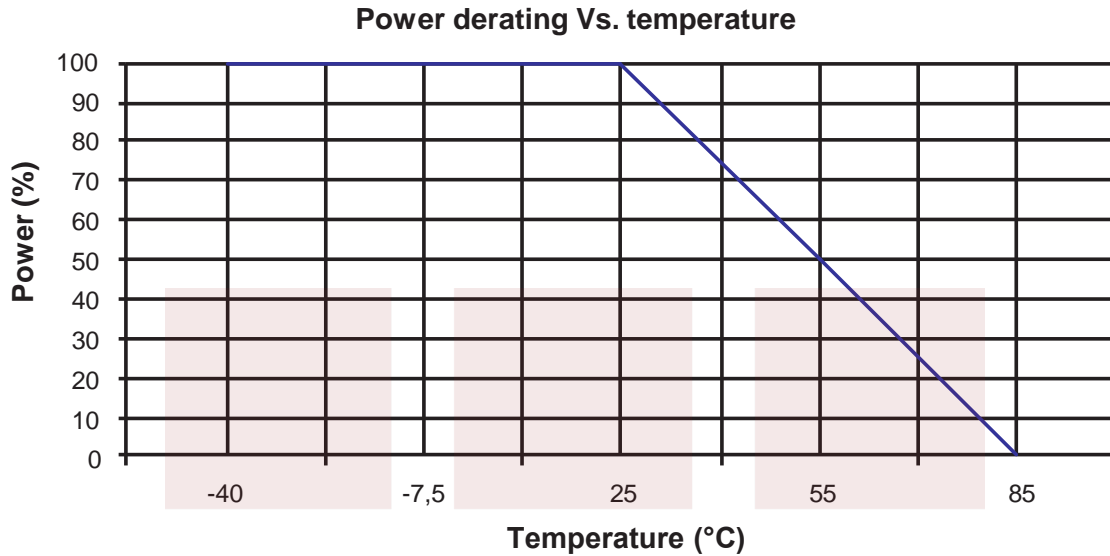


10 dB Fixed Attenuator 4.3-10 Male To 4.3-10 Female Up To 6 GHz Rated To 15 Watts from Fairview Microwave is in-stock and available to ship same-day. All of our RF/microwave products are available off-the-shelf from our ISO 9001:2008 certified facilities in Allen, Texas. Fairview Microwave is RF on-demand.

For additional information on this product, please click the following link: [10 dB Fixed Attenuator 4.3-10 Male To 4.3-10 Female Up To 6 GHz Rated To 15 Watts FMAP1001-10](#)

URL: <https://www.fairviewmicrowave.com/10db-fixed-attenuator-4.3-10-male-4.3-10-female-15-watts-fmap1001-10-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

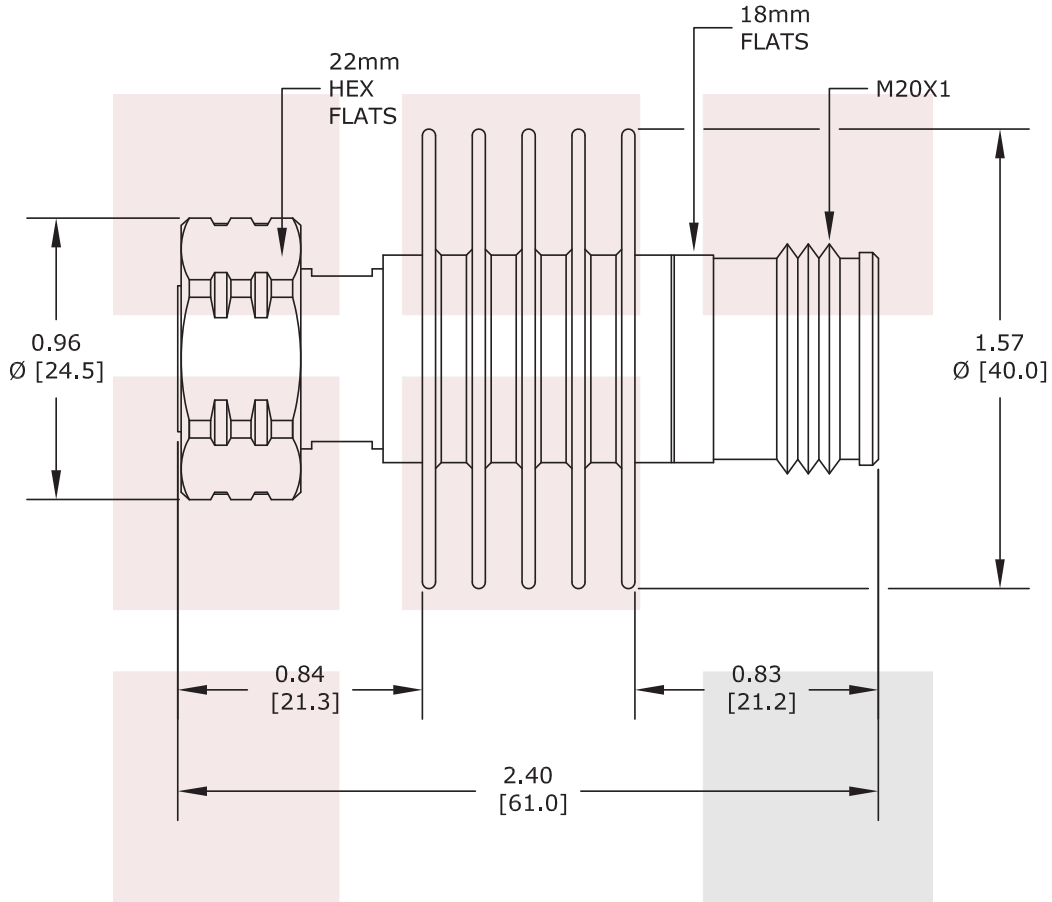

STANDARD TOLERANCES

.X ±0.2
 .XX ±0.1
 .XXX ±0.05

*STANDARD TOLERANCES APPLY ONLY TO DIMENSIONS IN INCHES

FAIRVIEW MICROWAVE INC.		NOTES: 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL. 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME. 3. DIMENSIONS ARE IN INCHES [mm].			
ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM		DWG NO		CAGE CODE	
TITLE 10 dB Fixed Attenuator 4.3-10 Male To 4.3-10 Female Up To 6 GHz Rated To 15 Watts		FMAP1001-10		3FKR5	
		CAD FILE	061417	SHEET	SCALE
				SIZE	A
				2233	