

SMA FLEXIBLE CABLES 6 GHZ LMR240

FMC0202240-XX

SPECIFICATIONS

CABLE ASSEMBLY:
VSWR: <1.2 TYPICAL @ 6 GHZ


RAW CABLE: LMR240
TYPICAL LOSS (EXCLUDING CONNECTORS)
@1GHz: 0.10 DB/FT
@3GHz: 0.17 DB/FT
@6GHz: 0.25 DB/FT

OUTER DIAMETER: .240"


CONNECTORS:

SMA:
MATERIAL BODY: NICKEL PLATED BRASS
CENTER CONTACT: BeCu
CONTACT PLATING: Au PLATING MIL-G-45204
INSULTAOR: TEFLON
INTERFACE: MIL-STD-348A

OP. TEMP: -55°C to +105°C

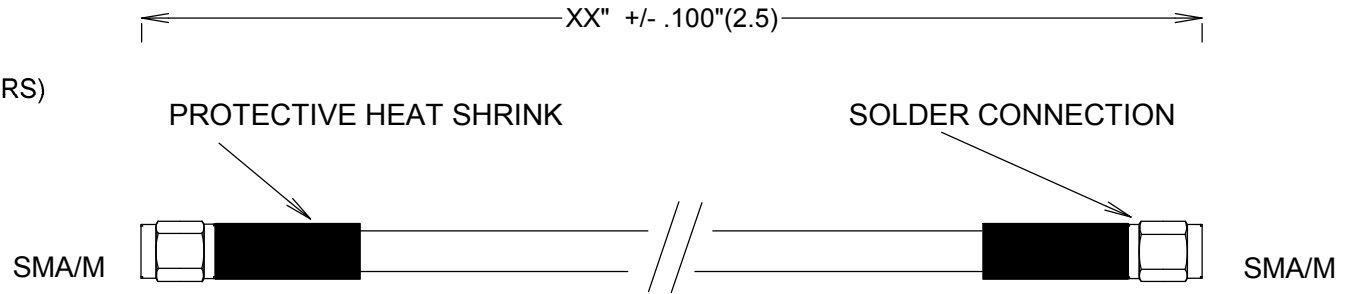

MEASUREMENTS BELOW ARE TYPICAL

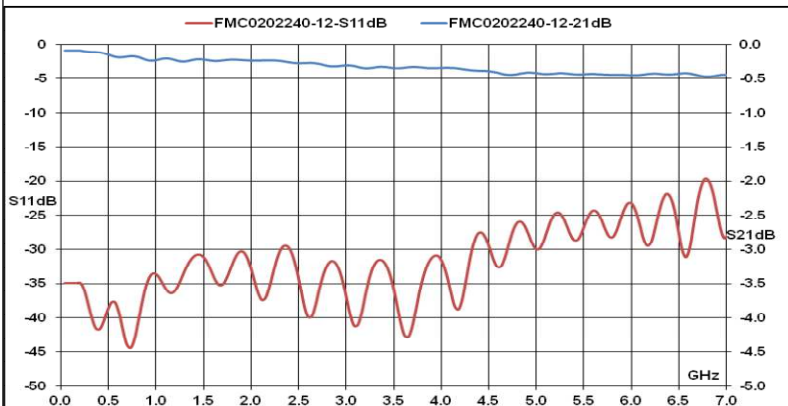

ALL DIMENSIONS IN inches(mm) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA FLEXIBLE CABLES 6 GHZ LMR240

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	FMC0202240-XX	A
SCALE		SHEET	