

Magnetic NMO Mount with 10 Ft. LMR195 Equivalent Cable & Reverse Polarity-SMA Plug Connector

Fairview Microwave's FMMA1-RSPA10 is an NMO-type mobile antenna magnetic mount, which is ideal when the portability of the antenna is required. This NMO antenna mount is constructed with a heavy-duty magnet to ensure secure mounting. No drilling is required for installation of this antenna mount, making it easy to fine-tune the antenna location. The magnetic base is easy to install and offers a temporary plug and play installation.

The FMMA1-RSPA10 mobile antenna mount from Fairview Microwave features a high-performance 10-foot black low-loss 195-series cable. This magnetic mount comes with a reverse polarity SMA plug connector and can be used for WLAN, Wi-Fi, public safety, and mobile RF applications. Our NMO mount has a length of 1.2 inch and a diameter of 3 inch. This magnetic mount with a rubber gasket is suitable for service vehicles, public transportation, law enforcement, fleet management, and mining and construction vehicles.

Fairview Microwave has the largest in-stock selection of NMO-type mobile antenna magnetic mount with the same-day shipment. Make your online purchase right now to take advantage of our same-day shipping. For further information on similar products, our expert technical support and knowledgeable sales team can help you get the ideal antenna mount with a reverse polarity SMA plug connector for your requirements.

Mechanical Specifications

Size	
Length	1.2 in [30.48 mm]
Width	3 in [76.2 mm]
Height	3 in [76.2 mm]
Weight	0.8 lbs [362.87 g]

Environmental Specifications

Magnetic NMO Mount with 10 Ft. LMR195 Equivalent Cable & Reverse Polarity-SMA Plug Connector from Fairview Microwave is in-stock and available to ship same-day. All of our RF/microwave products are available off-the-shelf from our ISO 9001:2008 certified facilities in Lewisville, Texas. Fairview Microwave is RF on-demand.

For additional information on this product, please click the following link: [Magnetic NMO Mount with 10 Ft. LMR195 Equivalent Cable & Reverse Polarity-SMA Plug Connector](#)

URL:

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.




Features:

- Magnetic NMO Mount
- Plug and Play Installation
- 3-inch diameter
- 10 Foot, Black Low-Loss LMR195 Equivalent
- RP-SMA Plug Connector
- RoHS Compliant

Applications:

- Service Vehicles
- Public Transportation
- Public Safety
- Mining & Construction
- Fleet Management

Fairview Microwave
301 Leora Ln., Suite 100
Lewisville, TX 75056
Tel: 1-800-715-4396 / (972) 649-6678
Fax: (972) 649-6689
www.fairviewmicrowave.com
sales@fairviewmicrowave.com

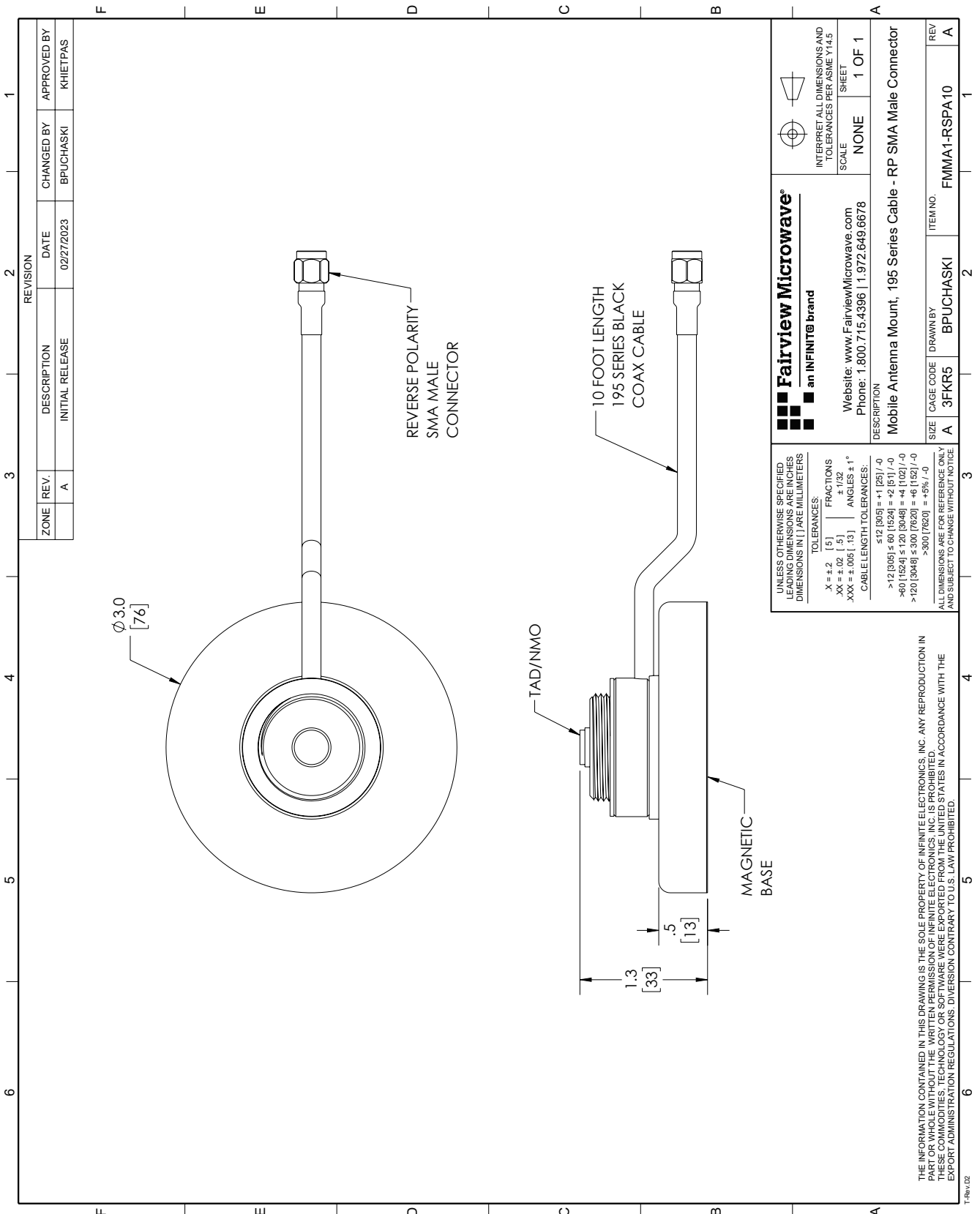

REVISION		DATE	CHANGED BY	APPROVED BY
ZONE	REV.	DESCRIPTION	INITIAL RELEASE	
	A			

<p>Fairview Microwave[®] an INFINIT[®] brand</p> <p>Website: www.FairviewMicrowave.com Phone: 1.800.715.4396 1.972.649.6678</p>	<p>INTERPRET ALL DIMENSIONS AND TOLERANCES PER ASME Y14.5</p>	<p>SCALE: NONE</p> <p>SHEET: 1 OF 1</p>
	<p>DESCRIPTION: Mobile Antenna Mount, 195 Series Cable - RP SMA Male Connector</p>	
<p>UNLESS OTHERWISE SPECIFIED, DIMENSIONS ARE IN INCHES. DIMENSIONS IN PARETHESISES ARE IN MILLIMETERS.</p> <p>TOLERANCES:</p> <p>.X = ±.2 [5] FRACTIONS ± 1/32</p> <p>.XX = ±.02 [5] ANGLES ± 1°</p> <p>.XXX = ±.005 [13]</p> <p>CABLE LENGTH TOLERANCES:</p> <p>≤ 12 [305] = ±1 [25] / -0</p> <p>> 12 [305] ≤ 60 [1524] = +2 [51] / -0</p> <p>> 60 [1524] ≤ 120 [3048] = +4 [102] / -0</p> <p>> 120 [3048] ≤ 300 [7620] = +6 [152] / -0</p> <p>> 300 [7620] = +5% / -0</p>	<p>SIZE: A</p> <p>CAGE CODE: 3FKR5</p> <p>DRAWN BY: BPUCHASKI</p> <p>ITEM NO.: FMMA1-RSPA10</p>	<p>REV: A</p>

THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF INFINITE ELECTRONICS, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF INFINITE ELECTRONICS, INC. IS PROHIBITED. EXPORT RESTRICTIONS, REGULATIONS, AND EXPORT ADMINISTRATION REGULATIONS CONTRARY TO U.S. LAW PROHIBITED.