

RG-214

SPECIFICATIONS

ELECTRICAL:


FREQUENCY: 11000 MHz
 IMPEDANCE: 50 OHMS
 CAPACITANCE (pF/m): 101.05
 VELOCITY PROPOGATION: 66%
 VOLTAGE(VMS): 5000 MAX

MIN BEND RADIUS: 1.57" (40mm)

OPERATING TEMPERATURE: -55°C to +200°C

MATERIAL:

CENTER CONDUCTOR: Si PLATED COPPER
 DIELECTRIC: SOLID POLYETHYLENE
 OUTER CONDUCTOR: DOUBLE Si PLATED COPPER BRAID

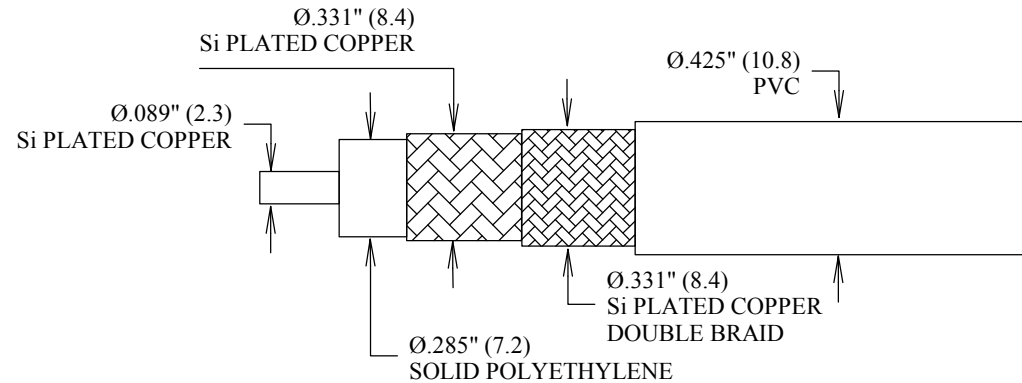

FREQUENCY(MHz)	ATTENUATION(>dB/1ft)
100	.02
400	.04
1000	.07
3000	.14
5000	.20
11000	.34

FAIRVIEW MICROWAVE INC.
 ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE
RG-214

ALL DIMENSIONS IN inches(MM) Typical	SIZE	CAGE CODE	DWG NO	REV
	A	3FKR5	RG-214	--
	SCALE		SHEET	