

RG-316 DS

SPECIFICATIONS

ELECTRICAL:


FREQUENCY: 3000 MHz
 IMPEDANCE: 50 OHMS
 CAPACITANCE (pF/m): 96.45
 VELOCITY PROPOGATION: 70%
 VOLTAGE(VMS): 1200 MAX

MIN BEND RADIUS: .591" (15mm)

OPERATING TEMPERATURE: -55°C to +200°C

MATERIAL:

CENTER CONDUCTOR: Si PLATED COPPER CLAD STEEL
 DIELECTRIC: PTFE
 OUTER CONDUCTOR: Si PLATED COPPER BRAID

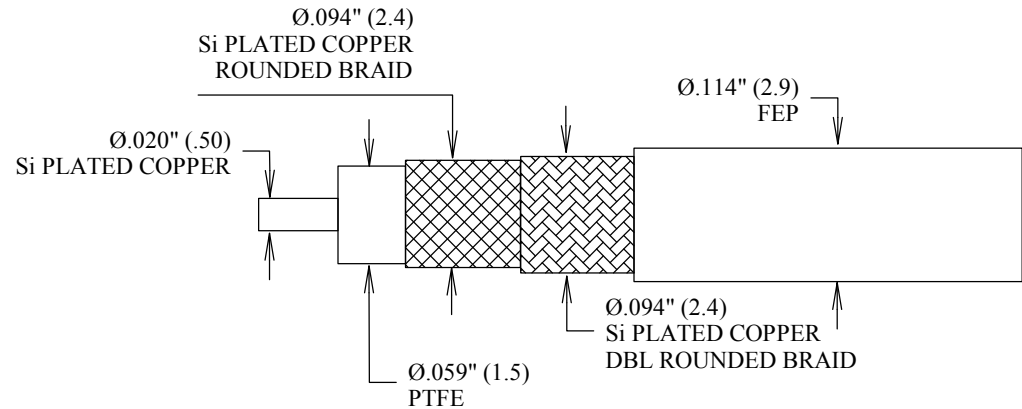

FREQUENCY(MHz)	ATTENUATION(>dB/1ft)
100	.08
400	.16
1000	.26
3000	.47

FAIRVIEW MICROWAVE INC.
 ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE
RG-316 DS

ALL DIMENSIONS IN inches(MM) Typical

SIZE A	CAGE CODE 3FKR5	DWG NO RG-316 DS	REV --
SCALE		SHEET	