

CONN SMA-M LMR200 CRIMP RA

SC7030

SPECIFICATIONS

ELECTRICAL:



FREQUENCY: 0-6 GHZ
 VSWR 1.21 MAX
 IMPEDANCE: 50 OHMS
 OP. TEMP RANGE: -55°C- +85°C

MECHANICAL:

MATERIAL BODY: BRASS
 CENTER CONTACT: BRASS
 CONTACT PLATING: Au PER MIL-G-45204
 INSULATOR: TEFLON

TORQUE: 3-5 IN-IBS

ROHS COMPLIANT

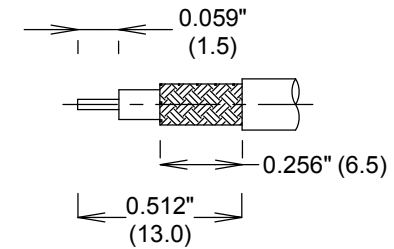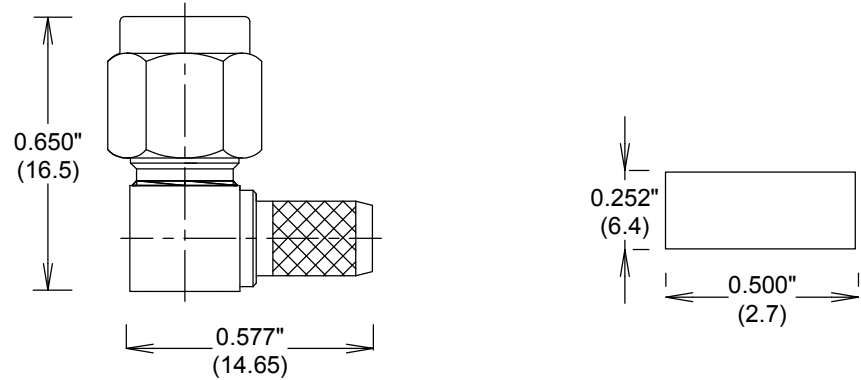

STRIPPING DIMENSIONS

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

CONN SMA-M LMR200 CRIMP RA

ALL DIMENSIONS IN inches(MM) Typical	SIZE	CAGE CODE	DWG NO	REV
	A	3FKR5	SC7030	--
	SCALE		SHEET	