

# SMA PLUG CRIMP RG316DS

SC7066

## SPECIFICATIONS

### ELECTRICAL:



 

FREQUENCY: 0-12.4 GHZ  
 VSWR 1.2:1 MAX  
 IMPEDANCE: 50 OHMS  
 OP. TEMP RANGE: -55C- +155C

### MECHANICAL:

MATERIAL BODY: PASS. STAINLESS STEEL  
 CENTER CONTACT: BRASS  
 CONTACT PLATING: Au PER MIL-G-45204  
 INSULATOR: TEFLON  
 INTERFACE: MIL-STD-348A

TORQUE: 7-10 IN-IBS

ROHS COMPLIANT

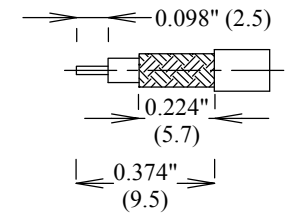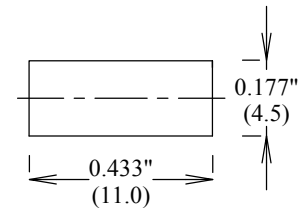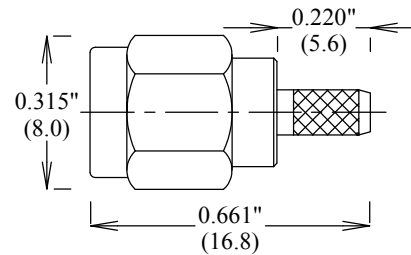

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**SMA PLUG CRIMP RG316DS**

SIZE	CAGE CODE	DWG NO	REV
<b>A</b>	<b>3FKR5</b>	<b>SC7066</b>	--
SCALE	SHEET		

ALL DIMENSIONS IN inches(MM) Typical