

# SSMC/PLUG TO SSMC/PLUG SOLDER BRAID CABLES 12GHZ 0.086"

SCA29086-XX


## SPECIFICATIONS

CABLE ASSEMBLY:  
FREQ: DC-12.4 GHZ

RAW CABLE: (HAVERHILL HFLEX .086 OR EQ)  
TYPICAL LOSS (EXCLUDING CONNECTORS)  
@ 1GHZ: 0.23 DB/FT  
@10GHZ: 0.80 DB/FT  
@18GHZ: 1.10 DB/FT

OUTER SHIELD DIAMETER: .086"  
OVERALL DIAMETER: .104"

CONNECTORS:  
SSMC: Au PLATED BRASS  
CONTACTS Au PLATING PER MIL-G-45204

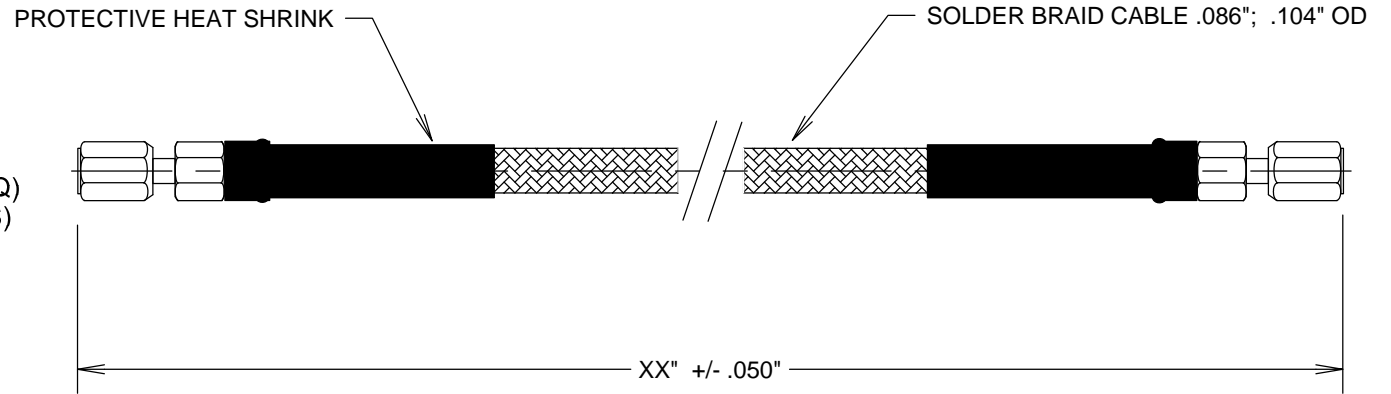

				<b>FAIRVIEW MICROWAVE INC.</b>	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				SSMC/PLUG TO SSMC/PLUG SOLDER BRAID 12GHZ 0.086" CABLES	
SIZE	CAGE CODE	DWG NO			REV
<b>A</b>	3FKR5	<b>SCA29086-XX</b>			--
SCALE					SHEET