

SMA FLEXIBLE CABLES LMR195 6GHZ

SCA49195-XX

SPECIFICATIONS


CABLE ASSEMBLY:
VSWR: <1.2 TYPICAL @ 6GHZ

RAW CABLE: (LMR195)
LOSS (EXCLUDING CONNECTORS)
@ 1GHZ: 0.16 DB/FT
@ 3GHZ: 0.22 DB/FT
@ 6GHZ: 0.39 DB/FT


OVERALL DIAMETER: .195"

CONNECTORS:
SMA: NICKEL PLATED BRASS
CONTACTS: Au PLATING 30μ-in
INTERFACE: MIL-STD-348A

TORQUE WRENCH: 5 IN-IBS

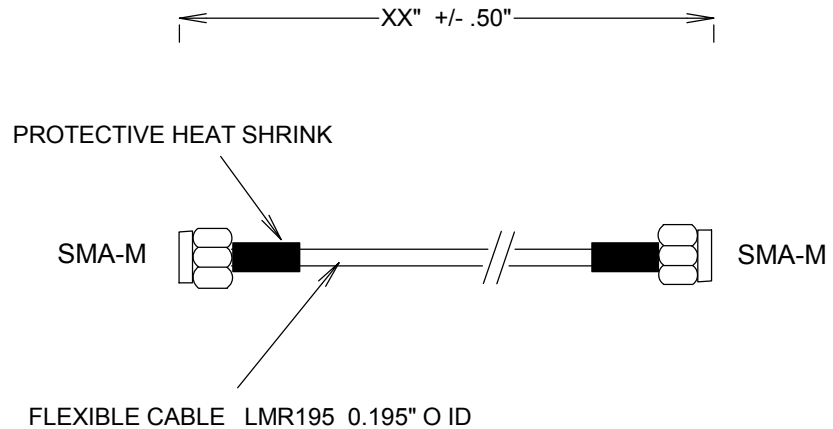

MEASUREMENTS BELOW ARE TYPICAL

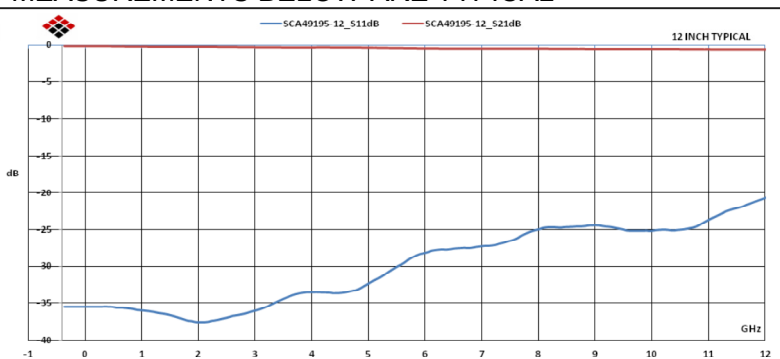

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.			
ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
TITLE			
SMA FLEXIBLE CABLES LMR195 6GHZ			
SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCA49195-XX	A
SCALE		SHEET	