

SMA FLEXIBLE CABLES LMR240 6GHZ

SCA49240

SPECIFICATIONS


CABLE ASSEMBLY:
VSWR: <1.2 TYPICAL @ 6GHZ

RAW CABLE:
LOSS (EXCLUDING CONNECTORS)
@ 1GHZ: 0.08 DB/FT
@ 3GHZ: 0.47 DB/FT
@ 6GHZ: 0.68 DB/FT


OVERALL DIAMETER: .195"

CONNECTORS:
SMA: NICKEL PLATED BRASS
CONTACTS: Au PLATING
INTERFACE: MIL-STD-348A

TROQUE WRENCH: 5 IN-IBS

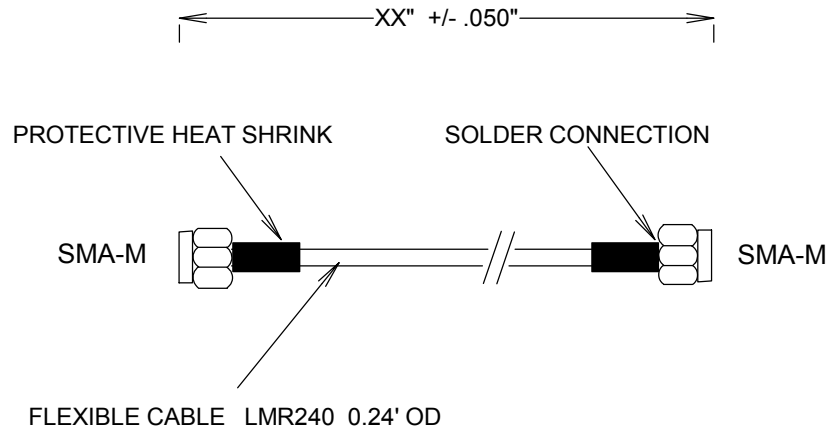

MEASUREMENTS BELOW ARE TYPICAL

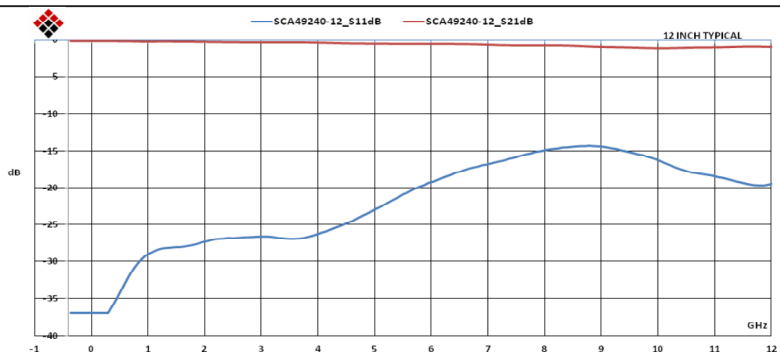

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA FLEXABLE CABLES LMR240 6GHZ

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCA49240	--
SCALE	SHEET		