

SMP/F-SMP/F/RA FLEXIBLE CABLES 18GHZ HSFLEX086

SCA69086-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.35:1 @ < 18GHZ TYPICAL

RAW CABLE: HUBER SUHNER FLEX .086
TYPICAL LOSS (EXCLUDING CONNECTORS)

@1GHZ: 0.23 DB/FT

@10GHZ: 0.8 DB/FT

@18GHZ: 1.1 DB/FT

CENTER CONDUCTOR DIAMETER: 0.0201"

OUTER SHIELD DIAMETER: .086"

OVERALL DIAMETER: 0.104"

CONNECTORS:

SMA: PASSIVATED STAINLESS STEEL


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A


SMP(GPOTm COMPATIBLE)

OP TEMP: -55-110°C

ROHS COMPLIANT

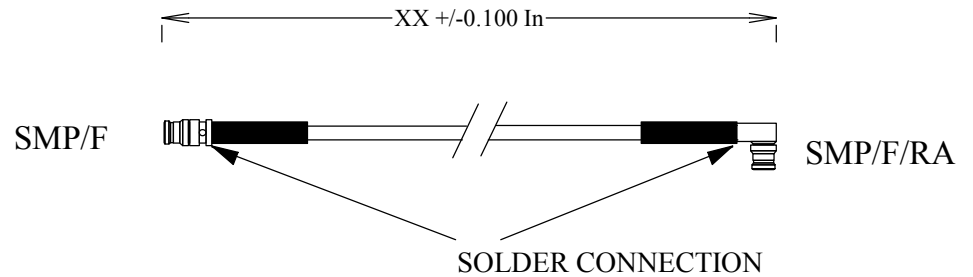

MEASUREMENTS BELOW ARE TYPICAL

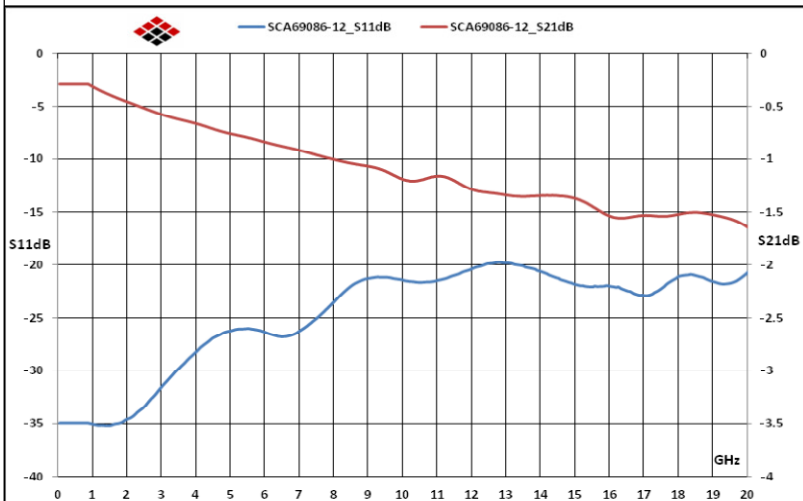

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMP/F-SMP/F/RA FLEXIBLE CABLES 18GHZ HSFLEX086

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCA69086-XX

REV

--

SCALE

SHEET