

# N/M -MCX/M-RA FLEXIBLE CABLES 3GHZ RG316

SCB111394-XX


## SPECIFICATIONS

CABLE ASSEMBLY:  
VSWR:1.2:1 @< 3GHZ TYPICAL

RAW CABLE: RG316  
TYPICAL LOSS (EXCLUDING CONNECTORS)  
@ 100MHZ: 0.08 DB/FT  
@1GHZ: 0.26 DB/FT  
@2GHZ: 0.38 DB/FT  
@3GHZ: 0.47 DB/FT

CONNECTORS:  
BRASS  
CONTACTS Au  
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C  
ROHS COMPLIANT

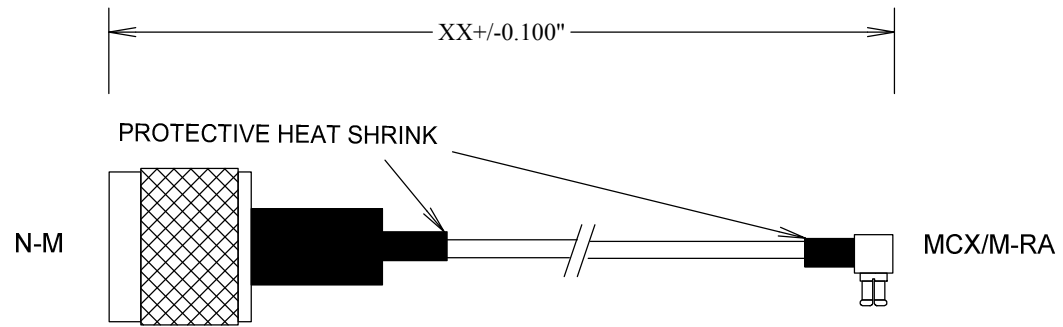

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M -MCX/M-RA FLEXIBLE CABLES 3GHZ RG316

SIZE	CAGE CODE	DWG NO	REV
<b>A</b>	3FKR5	<b>SCB111394-XX</b>	--
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical