

N/F - N/M- FLEXIBLE CABLES 6GHZ LMR240

SCB111531-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.2:1 @< 6GHZ TYPICAL

RAW CABLE: LMR240

TYPICAL LOSS (EXCLUDING CONNECTORS)

@1GHz: 0.081 DB/FT

@2GHz: 0.116 DB/FT

@6GHz: 0.205 DB/FT


@8GHz 0.238 DB/FT

CONNECTORS: BRASS


CONTACTS Au

INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

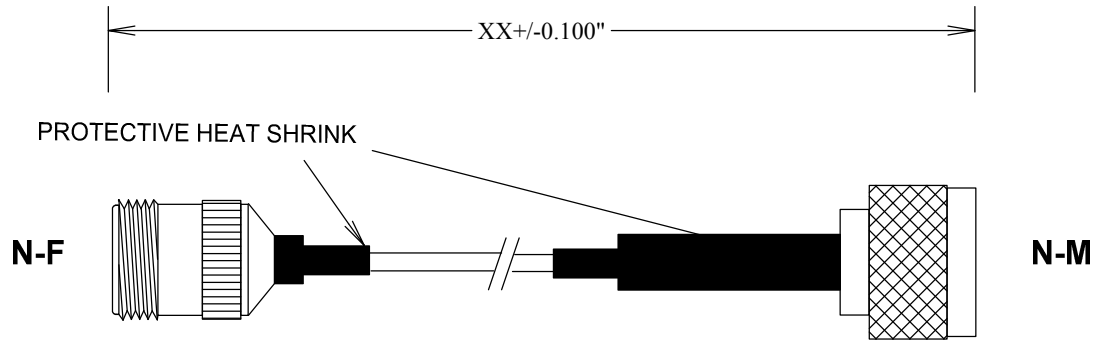

MEASUREMENTS BELOW ARE TYPICAL

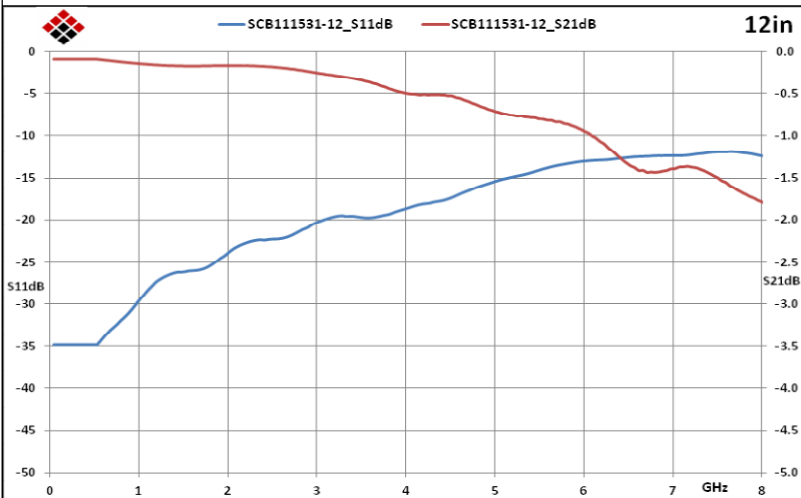

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.			
ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
TITLE			
N/F - N/M- FLEXIBLE CABLES 6GHZ LMR240			
SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB111531-XX	--
SCALE			SHEET