

QMA-PLUG-QMA-PLUG- FLEXIBLE CABLES 6GHZ LMR240

SCB112474-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.2:1 @ < 6GHZ TYPICAL

RAW CABLE: LMR240

TYPICAL LOSS (EXCLUDING CONNECTORS)

@1GHz: 0.081 DB/FT

@2GHz: 0.116 DB/FT

@6GHz: 0.205 DB/FT

@8GHz 0.238 DB/FT

CONNECTORS:


BRASS

CONTACTS Au

INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

ROHS COMPLIANT

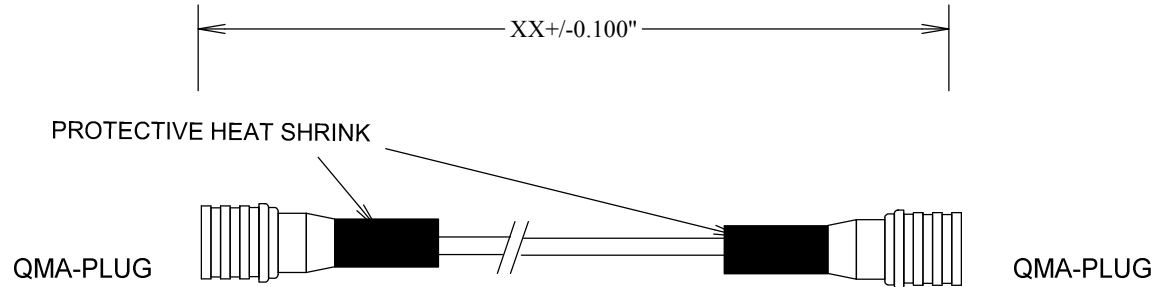

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**QMA-PLUG-QMA-PLUG- FLEXIBLE CABLES
6GHZ LMR240**

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB112474-XX	--
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical