

N/M - N/M FLEXIBLE CABLES 3GHZ RG316

SCB15130-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.3:1 @ < 3GHZ TYPICAL


RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHZ: 0.08 DB/FT
@ 1GHZ: 0.26 DB/FT
@ 2GHZ: 0.38 DB/FT
@ 3GHZ: 0.47 DB/FT

CONNECTORS: BRASS
CONTACTS Au PLATING 30μ-in
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

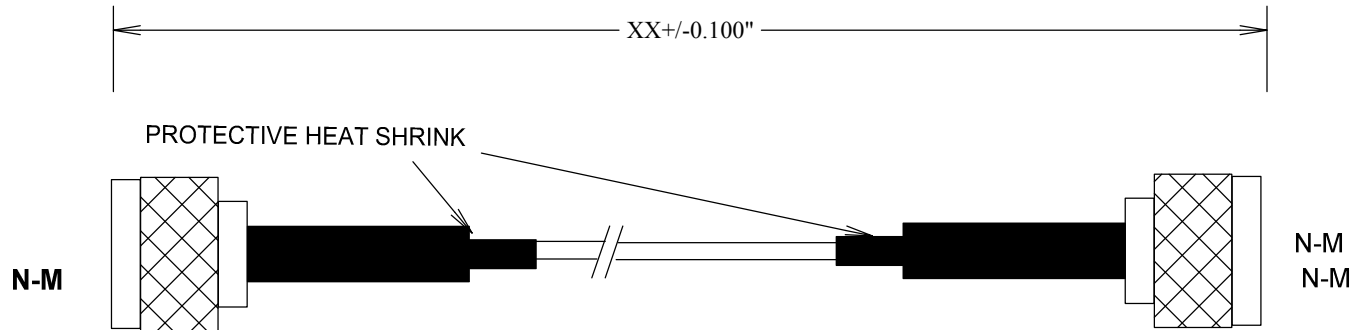

MEASUREMENTS BELOW ARE TYPICAL

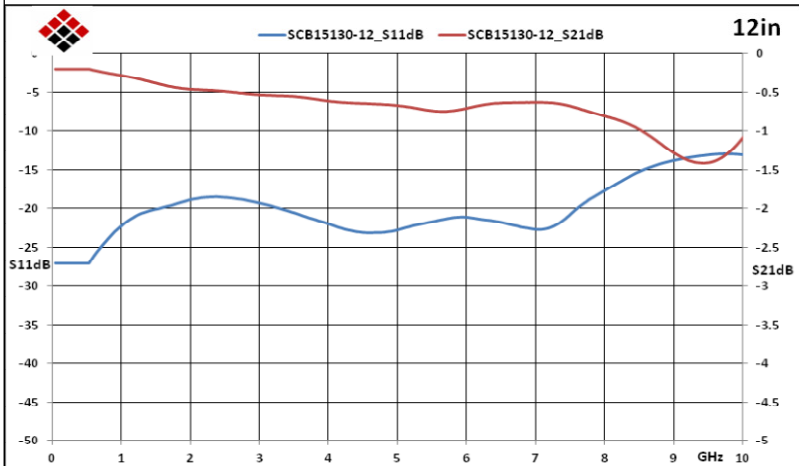

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M - N/M FLEXIBLE CABLES 3GHZ RG316

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB15130-XX	--
SCALE		SHEET	