

SMA/M - SMA/F BLKHD FLEXIBLE CABLES RG316

SCB15212-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR: 1.2:1 @ < 2GHz TYPICAL


RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHz: 0.08 DB/FT
@ 1GHz: 0.26 DB/FT
@ 2GHz: 0.38 DB/FT
@ 3GHz: 0.47 DB/FT

CONNECTORS:
SMA: BRASS torque 5-in-lbs
CONTACTS Au PLATING 30μ
INTERFACE: MIL-STD-348A

TEMPERATURE: -55°C to +200°C

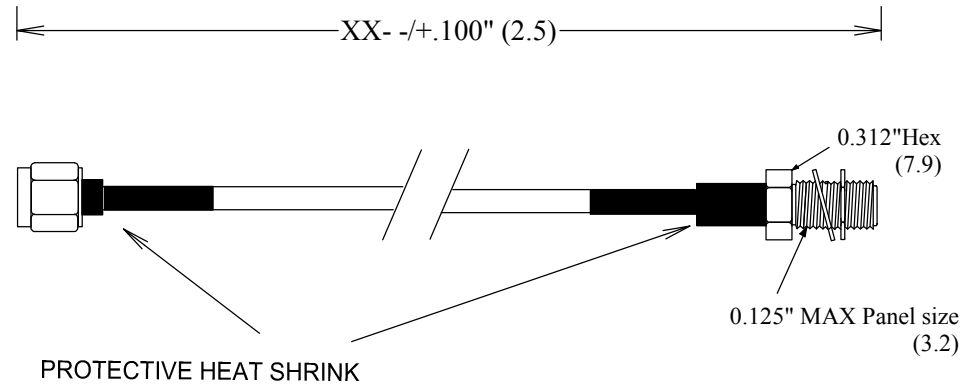

MEASUREMENTS BELOW ARE TYPICAL

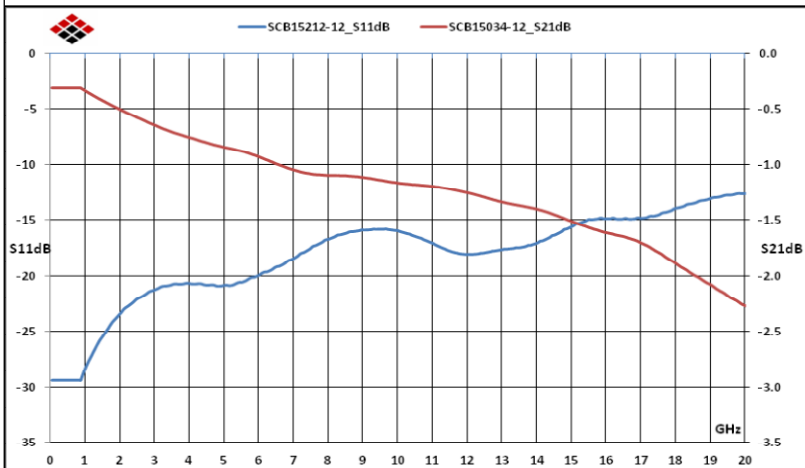

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M - SMA/F BLKHD FLEXIBLE CABLES RG316

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB15212-XX	--
SCALE		SHEET	