

SMA/M-N/M FLEXIBLE CABLES 3GHz RG316

SCB15226-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.2:1 @ < 3GHz TYPICAL

RAW CABLE: RG316

TYPICAL LOSS (EXCLUDING CONNECTORS)

@ 100MHz: 0.08 DB/FT

@ 1GHz: 0.26 DB/FT

@ 2GHz: 0.38 DB/FT

@ 3GHz: 0.47 DB/FT

CONNECTORS:


BODY: BRASS

SMA-CONNECTOR TORQUE 5-in-lbs


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A

TEMPERATURE: -55°C to +110°C

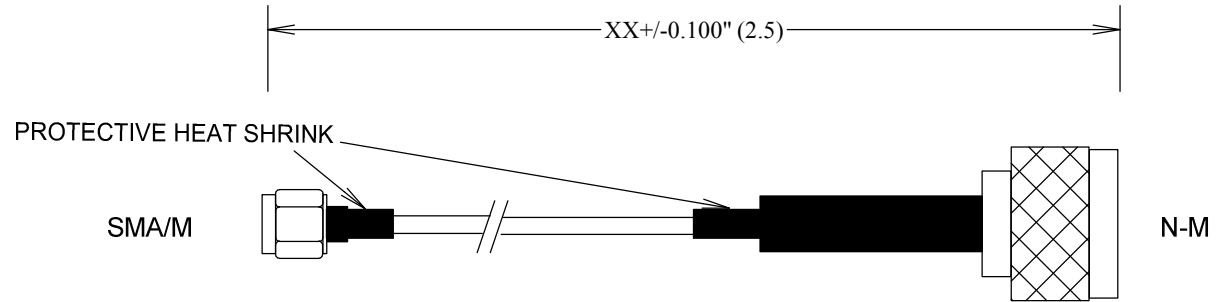

MEASUREMENTS BELOW ARE TYPICAL

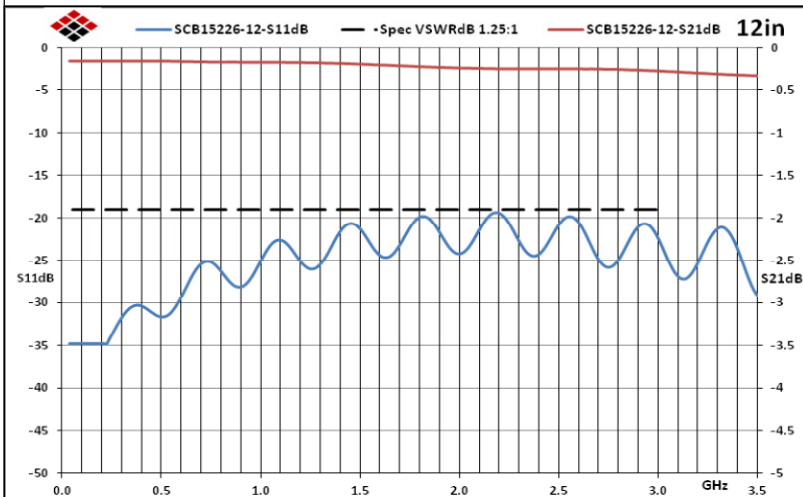

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M-N/M FLEXIBLE CABLES 3GHz RG316

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB15226-XX	--
SCALE			SHEET