

BNC/M - N/M FLEXIBLE CABLES 3GHZ RG316

SCB15549-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.2:1 @ < 3GHZ TYPICAL

RAW CABLE: RG316

TYPICAL LOSS (EXCLUDING CONNECTORS)

@ 100MHZ: 0.08 DB/FT

@1GHZ: 0.26 DB/FT

@2GHZ: 0.38 DB/FT

@3GHZ: 0.47 DB/FT

CONNECTORS:


BNC: BRASS

CONTACTS Au PLATING


INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

ROHS COMPLIANT

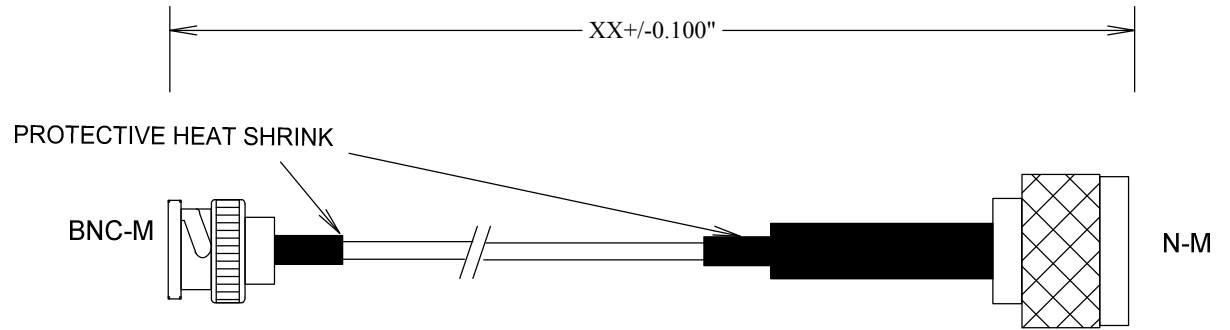

MEASUREMENTS BELOW ARE TYPICAL

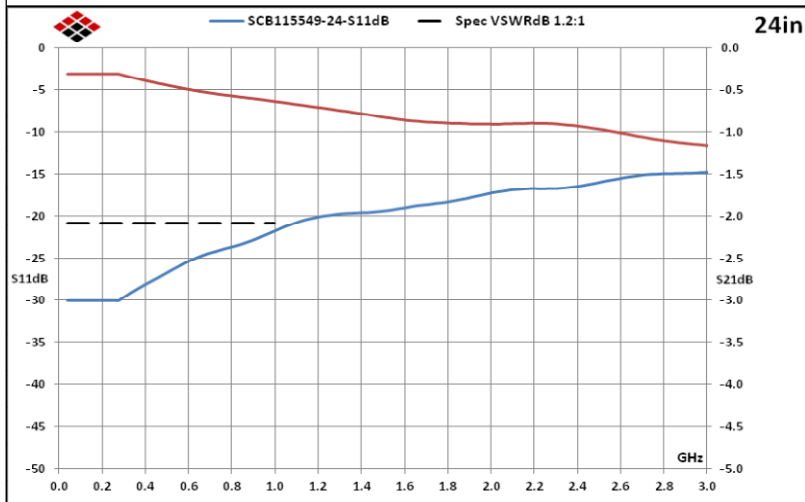

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

BNC/M - N/M FLEXIBLE CABLES 3GHZ RG316

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB15549-XX	--
SCALE			SHEET