

# BNC/M - N/M FLEXIBLE CABLES 6GHZ LMR240

SCB15558-XX

## SPECIFICATIONS

### CABLE ASSEMBLY:

VSWR:1.2:1 @ < 6GHZ TYPICAL

### RAW CABLE: LMR240


#### TYPICAL LOSS (EXCLUDING CONNECTORS)

@ 100MHz: 0.024 DB/FT  
 @1GHz: 0.081 DB/FT  
 @2GHz: 0.116 DB/FT  
 @3GHz: 0.143 DB/FT


### CONNECTORS:

BNC: BRASS  
 CONTACTS: Au PLATING  
 INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C  
 ROHS COMPLIANT

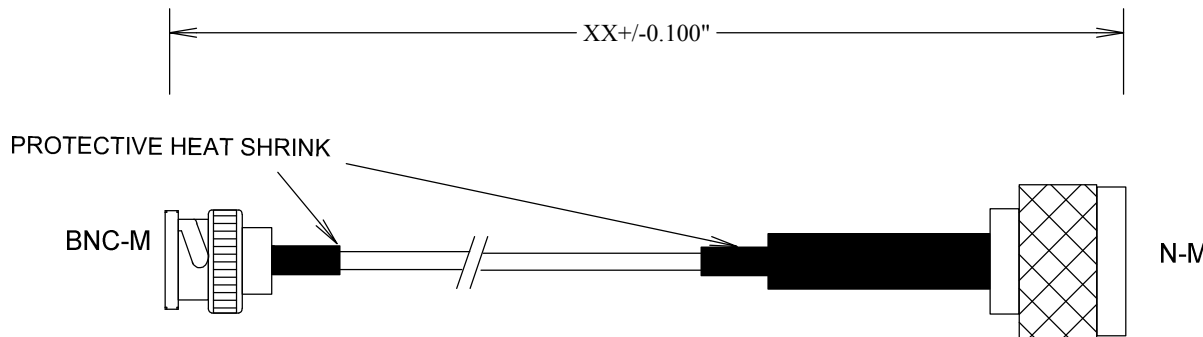

MEASUREMENTS BELOW ARE TYPICAL

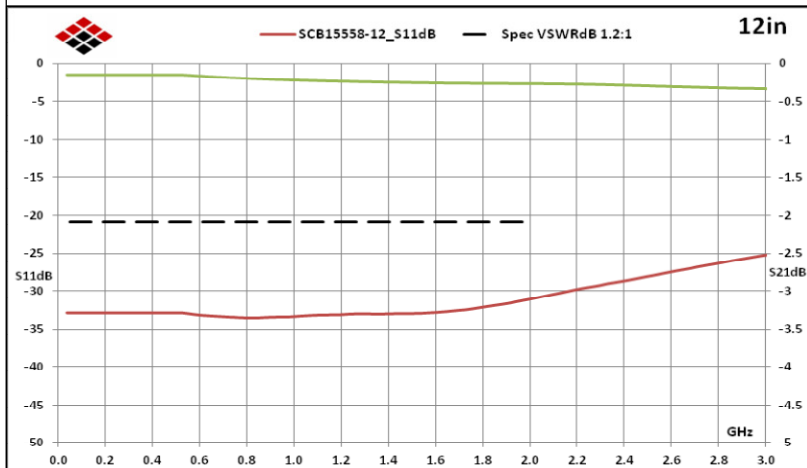

ALL DIMENSIONS IN inches(MM) Typical

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

BNC/M - N/M FLEXIBLE CABLES 6GHZ LMR240

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB15558-XX

REV

--

SCALE

SHEET