

N/M-N/M- FLEXIBLE CABLES 6GHZ LMR600

SCB15588-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.2:1 @ <6GHZ TYPICAL

RAW CABLE: LMR600

TYPICAL LOSS (EXCLUDING CONNECTORS)

@500MHz: 0.018 DB/FT

@1GHz: 0.026 DB/FT

@2GHz: 0.039 DB/FT

@4Ghz: 0.058 DB/FT


@6GHz: 0.074 DB/FT

CONNECTORS: BRASS


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

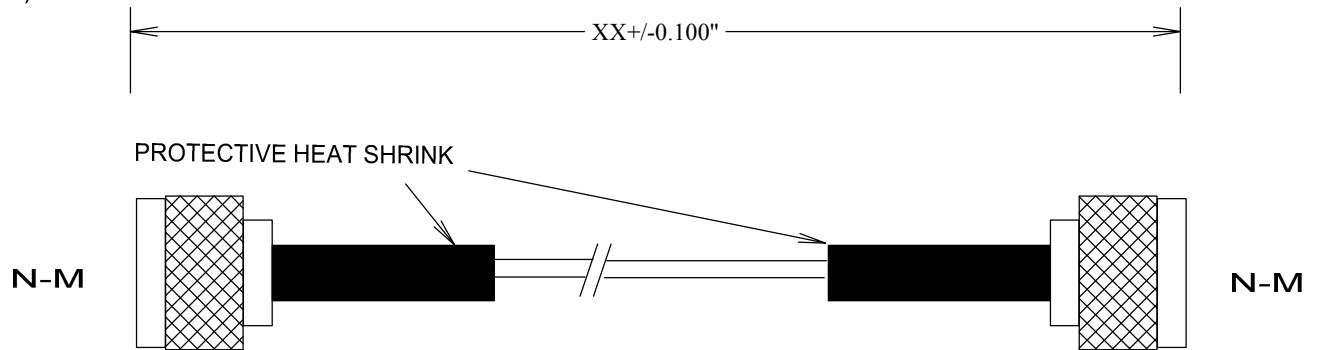

MEASUREMENTS BELOW ARE TYPICAL

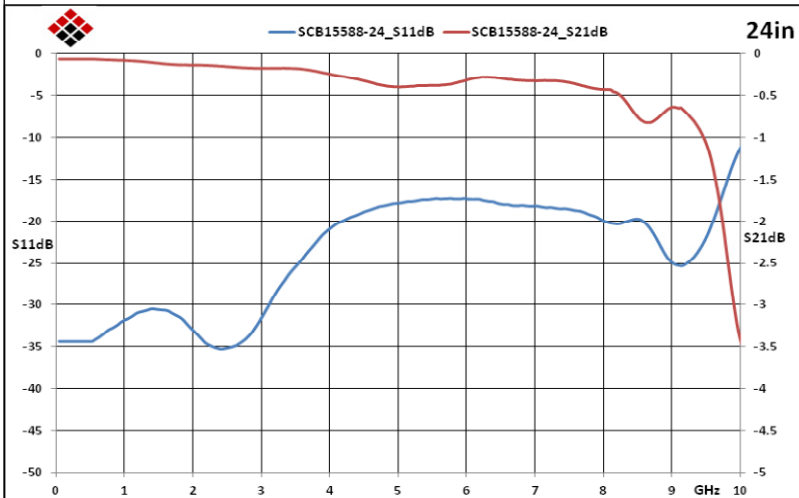

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M-N/M- FLEXIBLE CABLES 6GHZ LMR600

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB15588-XX

REV

--

SCALE

SHEET