



BNC/M - N/F FLEXIBLE CABLES 6GHZ LMR240

SCB18247-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @ < 6GHZ TYPICAL


RAW CABLE: LMR240
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHZ: 0.024 DB/FT
@ 1GHZ: 0.081 DB/FT
@ 2GHZ: 0.116 DB/FT
@ 3GHZ: 0.143 DB/FT

CONNECTORS:
BNC: BRASS
CONTACTS Au PLATING
INTERFACE: MIL-STD-348A

OP TEMP: -55 to +110°C
ROHS COMPLIANT

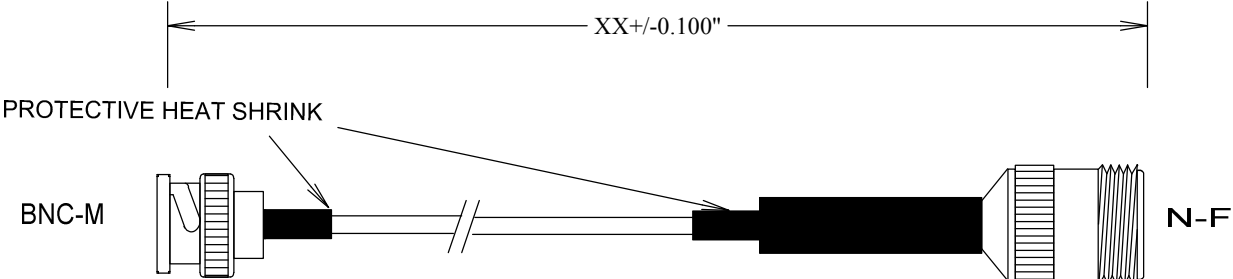

MEASUREMENTS BELOW ARE TYPICAL

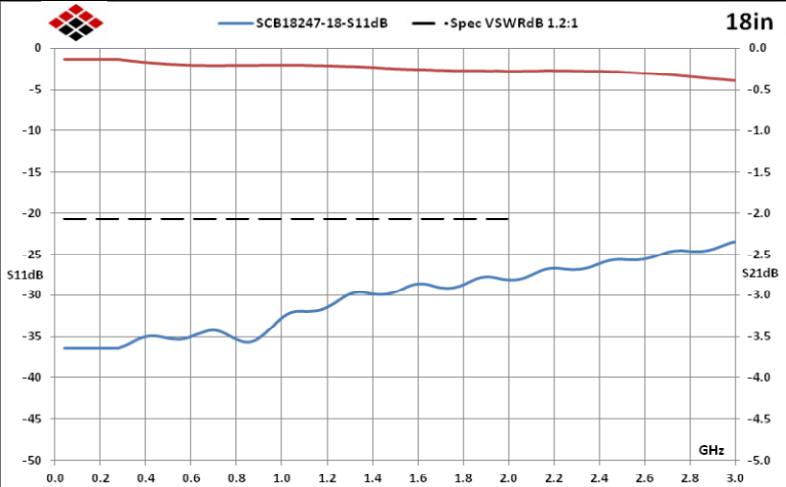

FAIRVIEW MICROWAVE INC.			
ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
TITLE BNC/M - N/F FLEXIBLE CABLES 6GHZ LMR240			
SIZE A	CAGE CODE 3FKR5	DWG NO SCB18247-XX	REV --
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical

