

SMA/M-N/M-RA FLEXIBLE CABLES 3GHz RG316

SCB18822-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR: 1.4:1 @ < 3GHz TYPICAL


RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@0.1GHz: 0.08 DB/FT
@1GHz: 0.29 DB/FT
@3GHz: 0.54 DB/FT

CONNECTORS:
BODY: BRASS
SMA-CONNECTOR TORQUE 5-in-lbs
CONTACTS Au PLATING
INTERFACE: MIL-STD-348A

TEMPERATURE: -55°C to +110°C

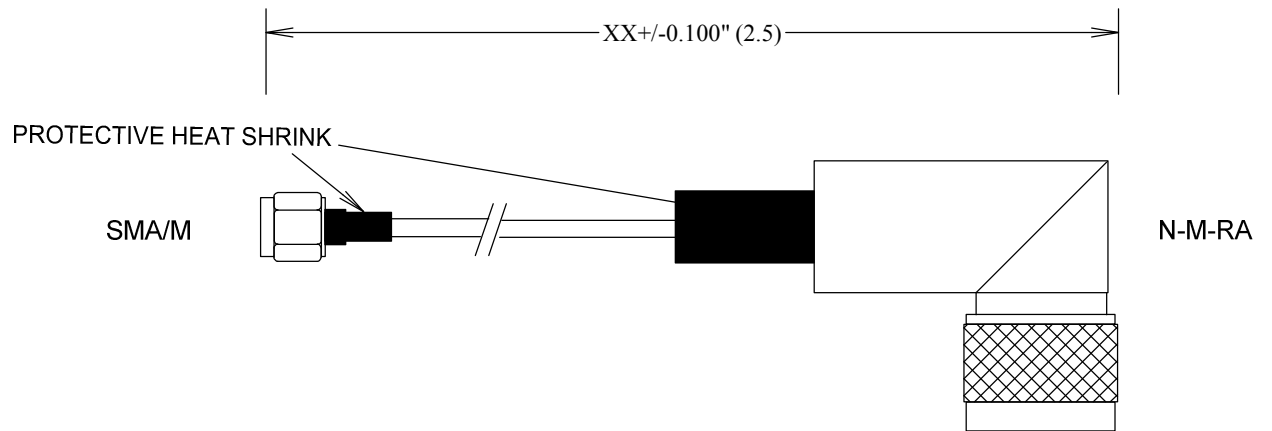

MEASUREMENTS BELOW ARE TYPICAL

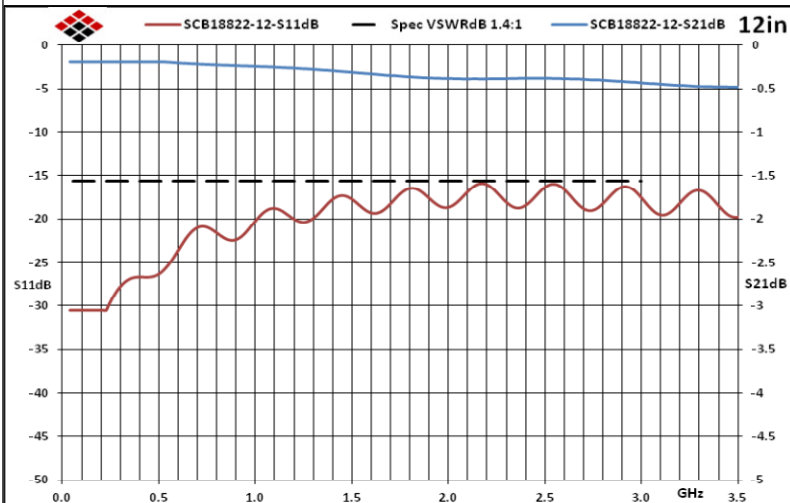

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.			
ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
TITLE SMA/M-N/M-RA FLEXIBLE CABLES 3GHz RG316			
SIZE A	CAGE CODE 3FKR5	DWG NO SCB18822-XX	REV --
SCALE		SHEET	