

SMA/M-MMCX/M FLEXIBLE CABLE RG174

SCB18842-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR: 1.25:1 @ <3GHz TYPICAL

RAW CABLE: RG174

TYPICAL LOSS (EXCLUDING CONNECTORS)

@0.1GHz 0.08 DB/FT

@0.5GHz 0.19 DB/FT

@1GHz 0.27 DB/FT

@2GHz 0.39 DB/FT

@3GHz 0.49 DB/FT

CONNECTORS: BRASS


SMA torque 5-in-lbs

CONTACTS Au PLATING


INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

ROHS COMPLIANT

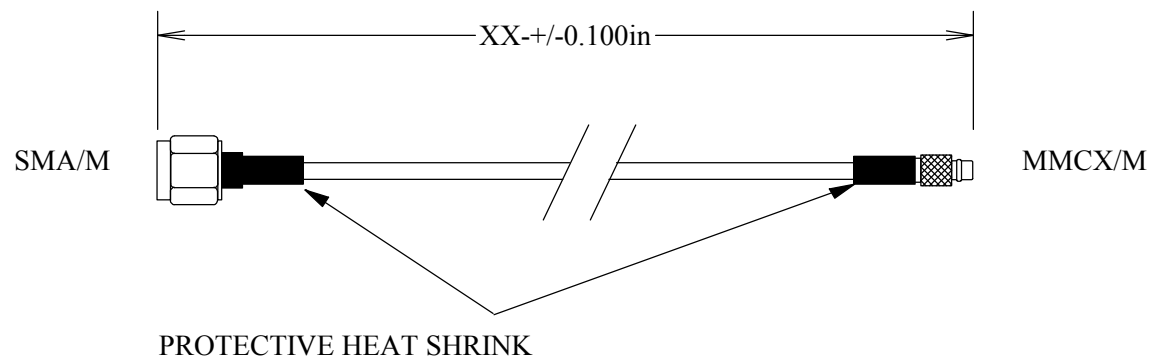

MEASUREMENTS BELOW ARE TYPICAL

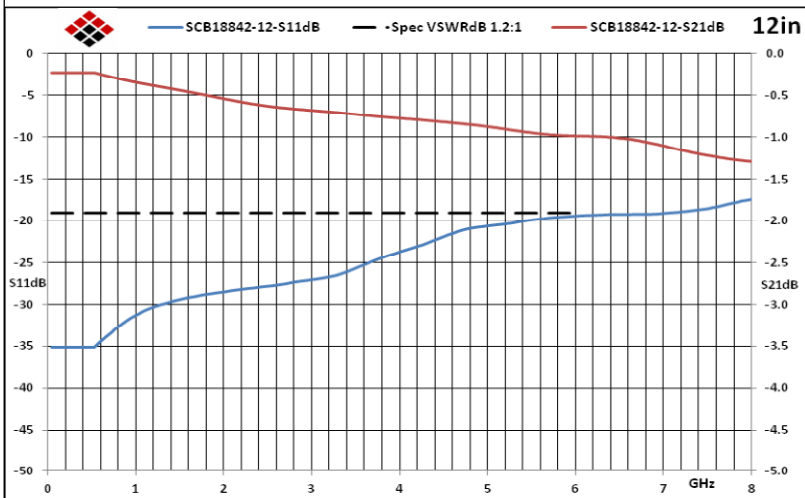

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M-MMCX/M FLEXIBLE CABLE RG174

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB18842-XX

REV

--

SCALE

SHEET