



SMA/F-MMCX/M FLEXIBLE CABLES RG316

SCB18856-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @<3GHZ TYPICAL


RAW CABLE: RG316DS
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHZ: 0.08 DB/FT
@1GHZ: 0.26 DB/FT
@2GHZ: 0.38 DB/FT
@3GHZ: 0.47 DB/FT

CONNECTORS: BRASS
SMA: Mating torque 5-in-lbs
CONTACTS Au PLATING 30uin
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C
ROHS COMPLIANT

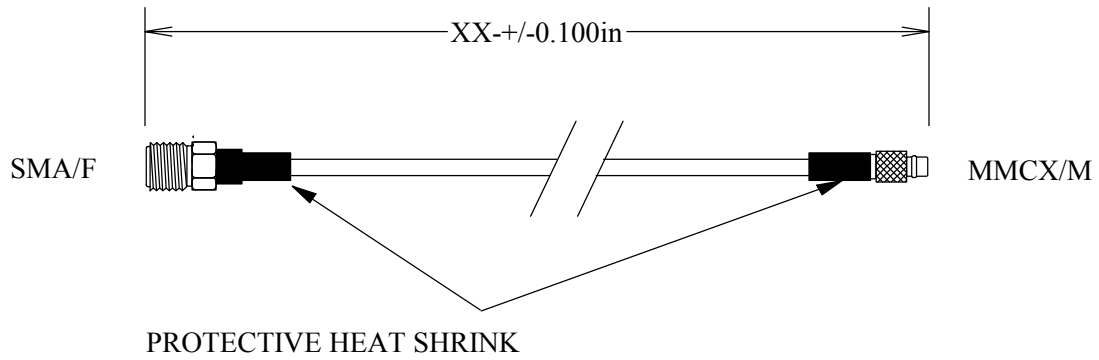

MEASUREMENTS BELOW ARE TYPICAL

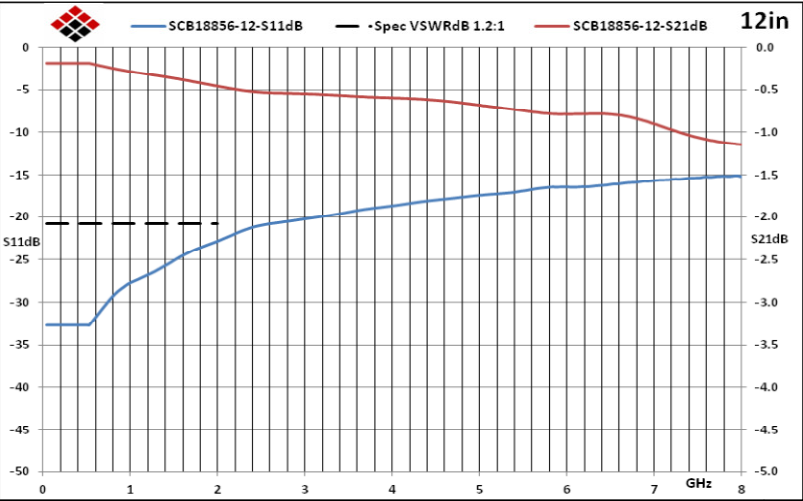

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE			
SMA/F-MMCX/M FLEXIBLE CABLES RG316			
SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB18856-XX	--
SCALE		SHEET	

