

N/M-N/M HF086 FLEXIBLE CABLES 12GHZ

SCF32086-XX

SPECIFICATIONS

CABLE ASSEMBLY

RAW CABLE: HF086

VSWR: 1.4:1 @ <12 GHZ TYPICAL

TYPICAL LOSS (EXCLUDING CONNECTORS)

0.14 DB/FT@400MHz

0.23 DB/FT@1GHz

0.39 DB/FT@3GHz

0.52 DB/FT@5GHz

0.8 DB/FT@10GHz


0.9 DB/FT@12GHz

CONNECTORS: BRASS


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A

TEMPERATURE: -55°C to +110°C

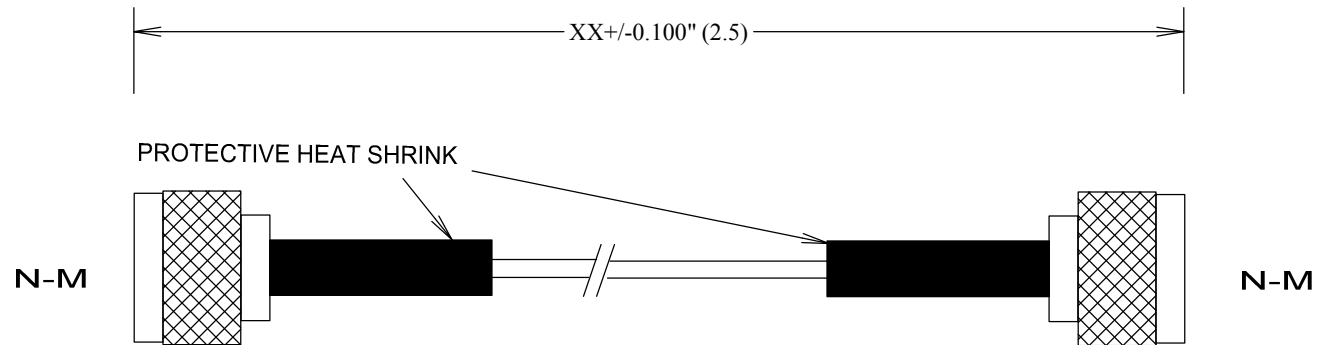

MEASUREMENTS BELOW ARE TYPICAL

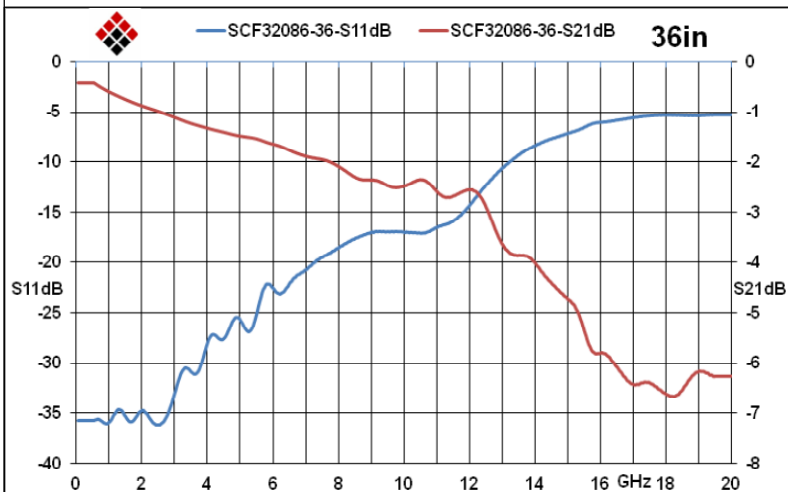

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M-N/M HF086 FLEXIBLE CABLES 12GHZ

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCF32086-XX

REV

A

SCALE

SHEET