

# SMP/F-SMA/M FLEXIBLE CABLES HS086

SCH72086-XX

## SPECIFICATIONS

**CABLE ASSEMBLY:**

VSWR:1.35:1 @ < 18GHZ TYPICAL

**RAW CABLE: HAVERHILL HC086**

TYPICAL LOSS (EXCLUDING CONNECTORS)

@1GHz:

@10GHz:

@18GHz:

CENTER CONDUCTOR DIAMETER: 0.0201"

OUTER SHIELD DIAMETER: .086"

OVERALL DIAMETER: 0.104"

**CONNECTORS:**

SMA: Nickel PLATED BRASS


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A


SMP(GPOtm COMPATIBLE)

Au PLATED BeCu

ROHS COMPLIANT

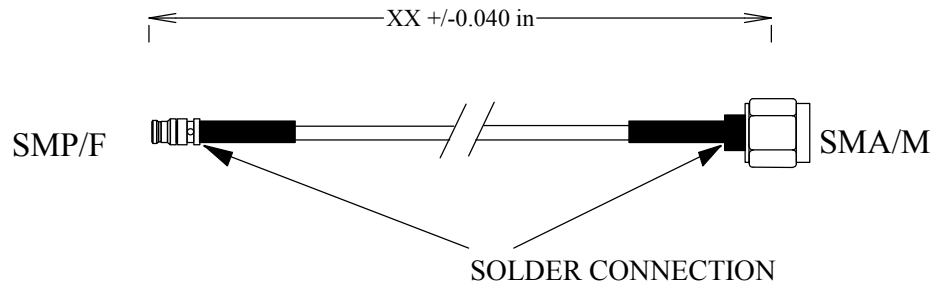

MEASUREMENTS BELOW ARE TYPICAL

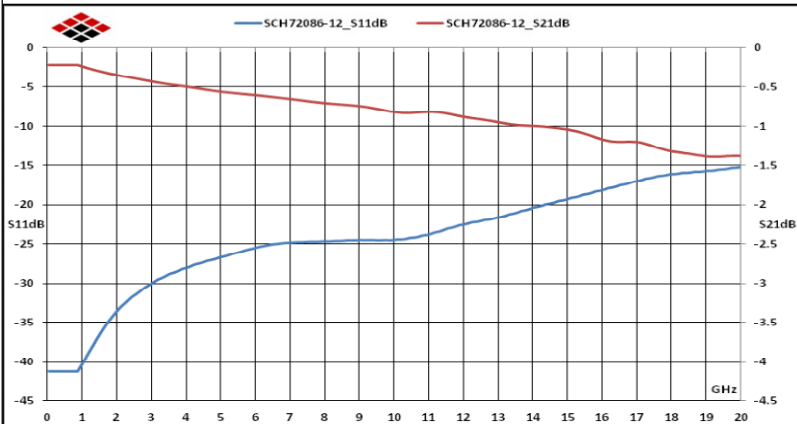

ALL DIMENSIONS IN inches(MM) Typical

### FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMP/F-SMA/M FLEXIBLE CABLES HS086

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCH72086-XX	--
SCALE		SHEET	