

MIXER RF 800-2500 IF 0-400MHZ

SFM0825

SPECIFICATIONS

ELECTRICAL

FREQUENCY:

LO/RF: 800-2500 MHZ

IF: DC-400 MHZ

LO DRIVE: +7 dBm Typ.

CONVERSION LOSS : 8.0 dBm MAX

L/R ISOLATION: 20 dB MIN

L/I ISOLATION: 15 dB MIN


ROHS COMPLIANT

PORT CONFIGURATION

RF: 1

LO: 3

IF: 2

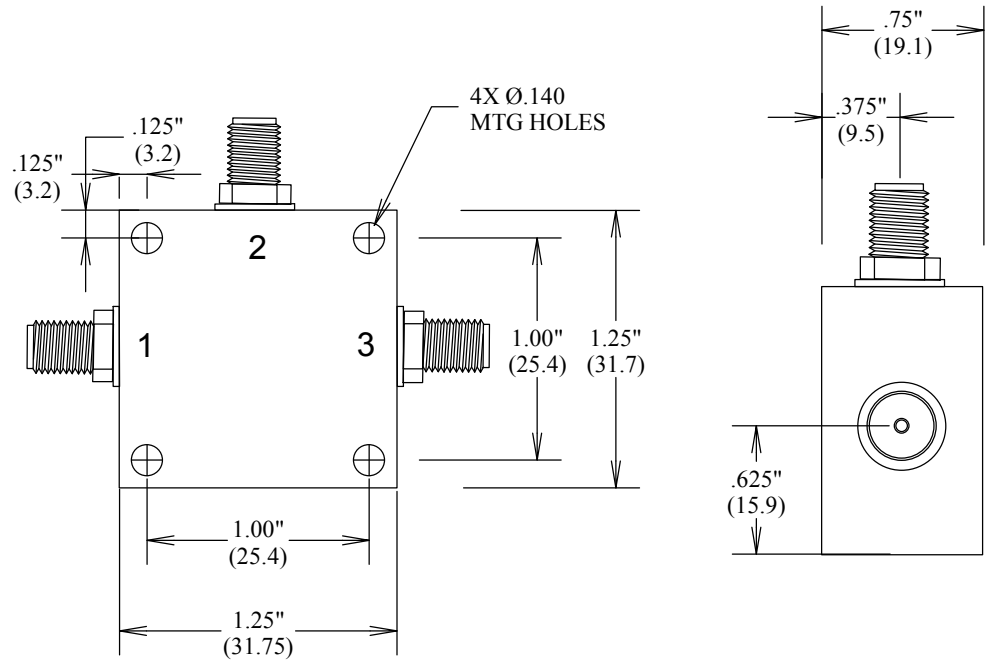

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

MIXER RF 800-2500 IF 0-400MHZ

ALL DIMENSIONS IN inches(MM) Typical				SIZE	CAGE CODE	DWG NO	REV
				A	3FKR5	SFM0825	--
				SCALE			SHEET