

2.92 FORMABLE SEMIRIGID CABLES

SPECIFICATIONS


CABLE ASSEMBLY:
 FREQUENCY: 0-40GHZ
 VSWR 1.35:1 MAX @ 40GHZ

CABLE:
 086 HAVERHILL .086 SOLID AI OR EQ
 086B MICROCOAX UT-85-FORM (TIN DIPPED)
 DIAMETER: .086"
 LOSS: 1.3 DB/FT 20GHZ (EXC CONN'S)
 LOSS: 1.8 DB/FT 40GHZ (EXC CONN'S)

CONNECTORS:
 2.92mm MALE
 BODY: PASS. STAINLESS STEEL
 PIN: Au PLATED MIL-G-45204
 8-10 in-lbs TORQUE


TEMPERATURE: -55 - +100°C

ROHS COMPLIANT

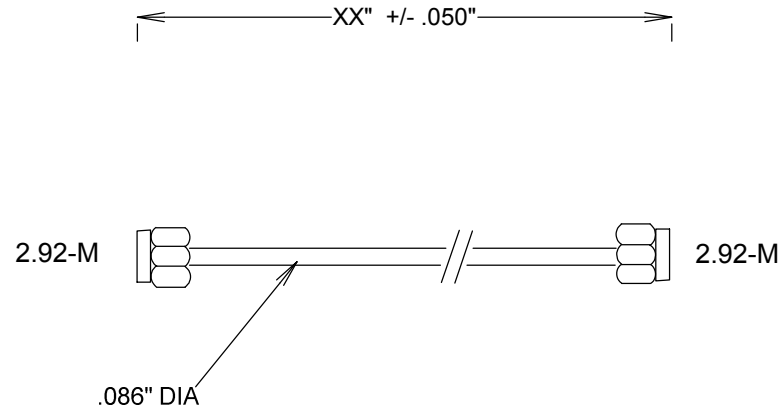

THESE CABLES CAN BE FORMED BY HAND;
 THEY RETAIN THEIR SHAPE UPON FORMING

MEASUREMENTS BELOW ARE TYPICAL

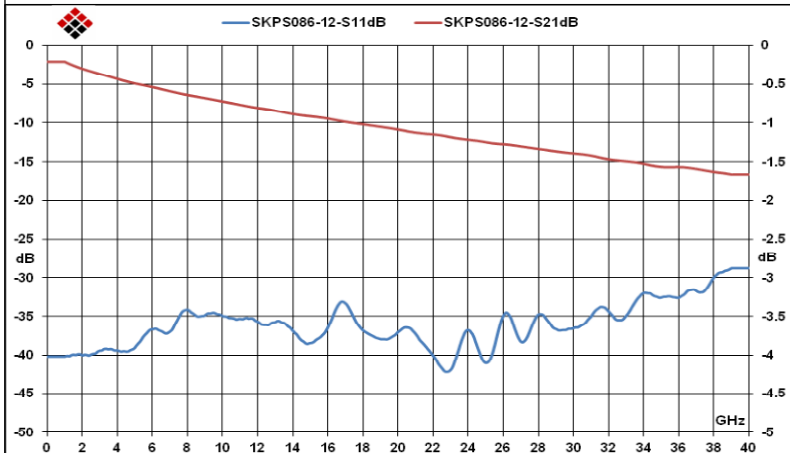

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

2.92 FORMABLE SEMIRIGID CABLES

SIZE A	CAGE CODE 3FKR5	DWG NO SKPS086, SKPS086B	REV A
------------------	--------------------	------------------------------------	-----------------

SCALE

SHEET