

SSMC PLUG-PLUG

SM2186


SPECIFICATIONS

ELECTRICAL
50 OHMS
FREQUENCY: 0-12 GHZ
VSWR 1.25:1 MAX @ 12 GHZ


BODY: NICKEL PLATED BRASS
FEMALE CONTACTS: BeCu, Au PLATING MIL-G-45204
MALE CONTACTS: BRASS, Au PLATING MIL-G-45204

TEMPERATURE RANGE: -55° to+120°C

ROHS COMPLIANT

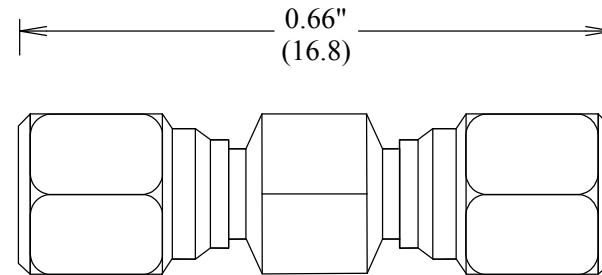

X3 0.156HEX

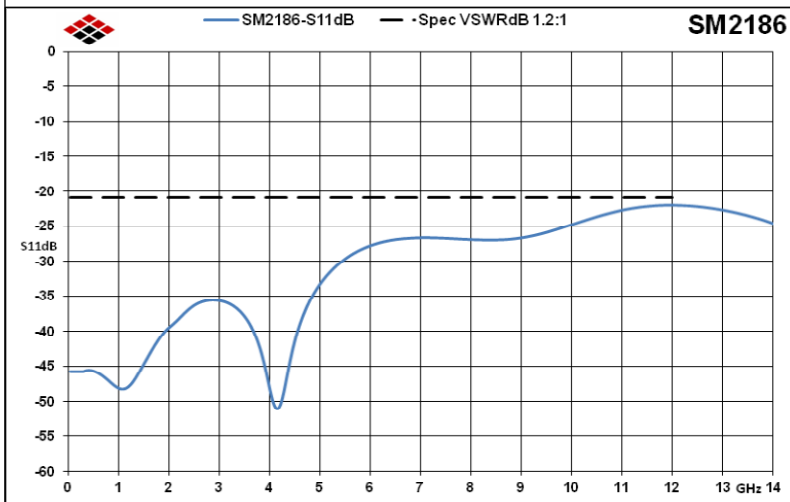

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.			
ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
TITLE			
SSMC PLUG-PLUG			
SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SM2186	A
SCALE		SHEET	