

C-MALE TO BNC JACK ADAPTER

SM3537

SPECIFICATIONS

ELECTRICAL


FREQUENCY: 0-2 GHZ
IMPEDANCE: 50 OHMS
VSWR: 1.40:1 MAX

ENVIRONMENTAL

-40°C TO +120 °C

MATERIALS

BODY: NICKEL PLATED BRASS
CONTACT PLATING: Au PER MIL G 45204
CENTER CONTACTS: BeCu
INSULATOR: PTFE
INTERFACE: MIL-STD-883
ROHS COMPLIANT

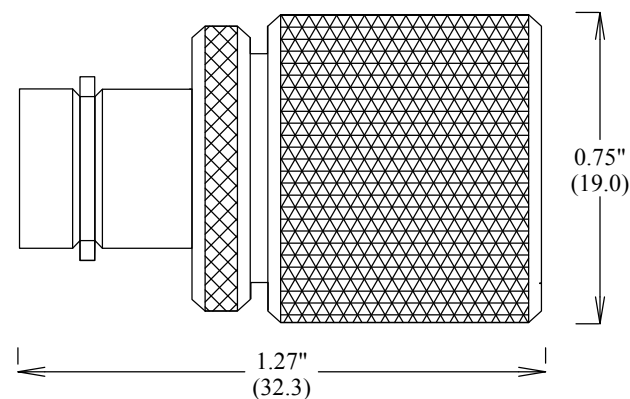

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

C-MALE TO BNC JACK ADAPTER

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SM3537	--
SCALE	SHEET		

ALL DIMENSIONS IN inches(MM) Typical