

MCX-BNC ADAPTERS 6GHZ

SM3660

SPECIFICATIONS

ELECTRICAL

FREQUENCY: 0-6 GHZ

IMPEDANCE: 50 OHMS

VSWR: 1.2:1 MAX @ 0-2GHZ

1.35:1 MAX @ 2-6GHZ

MECHANICAL

MATERIAL BODY: NICKEL PLATED BRASS

MATERIAL CONTACT MCX: BeCu


MATERIAL CONTACT BNC: BRASS

CONTACT PLATING: Au PER MIL-G-45204

INSULATOR: TEFLON

INTERFACE: MIL-STD-348

BNC-F

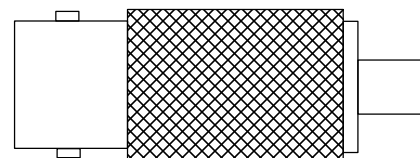


MMCX-J

0.45"
(11.4)

1.24"
(31.5)

SM3660

MEASUREMENTS BELOW ARE TYPICAL

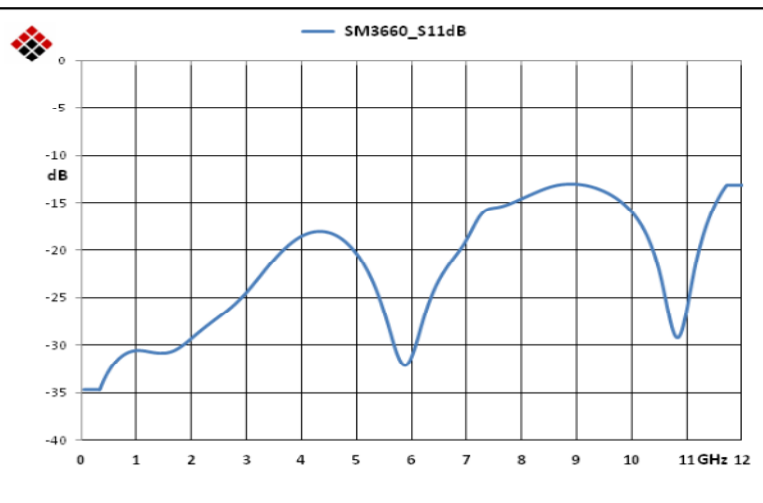

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

MCX-BNC ADAPTERS 6GHZ

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SM3660	--
SCALE		SHEET	