

SMA/M-TNC/F FLANGE 11GHZ ADAPTER

SM4748

SPECIFICATIONS

ELECTRICAL:
 FREQUENCY: 0-11 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.25:1 MAX



MECHANICAL:
 MATERIALS SMA BODY: PASS. STAINLESS STEEL
 MATERIALS TNC BODY: NICKEL PLATED BRASS
 CONTACTS: BeCu
 CONTACT PLATING: Au per MIL-G-45204
 DIELECTRIC: TEFLON
 INTERFACE MIL-STD-348A

Recommended SMA coupling net torque; 7.9 in-lbs

OPERATING TEMPERATURE RANGE: -65°C TO +165°C

ROHS COMPLIANT

MEASUREMENTS BELOW ARE TYPICAL

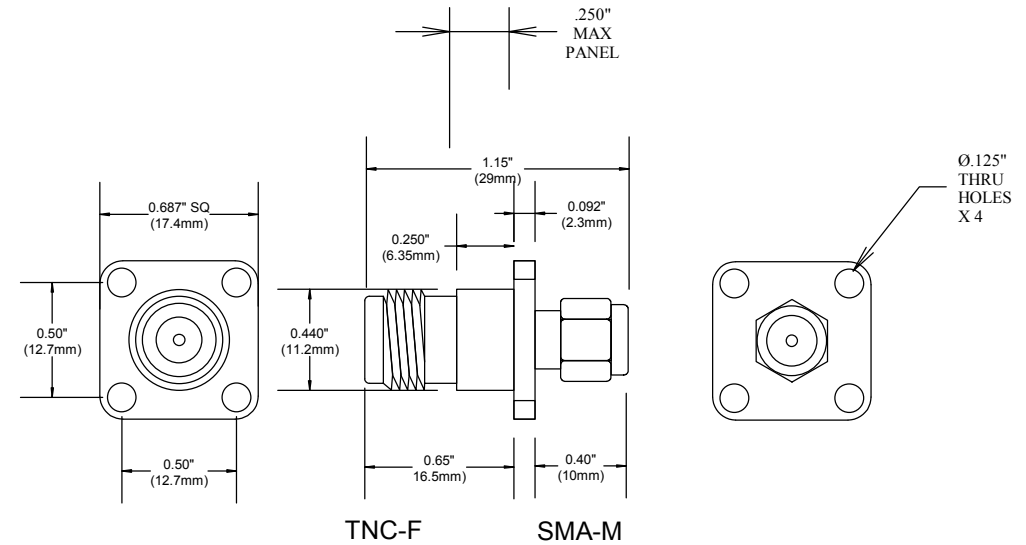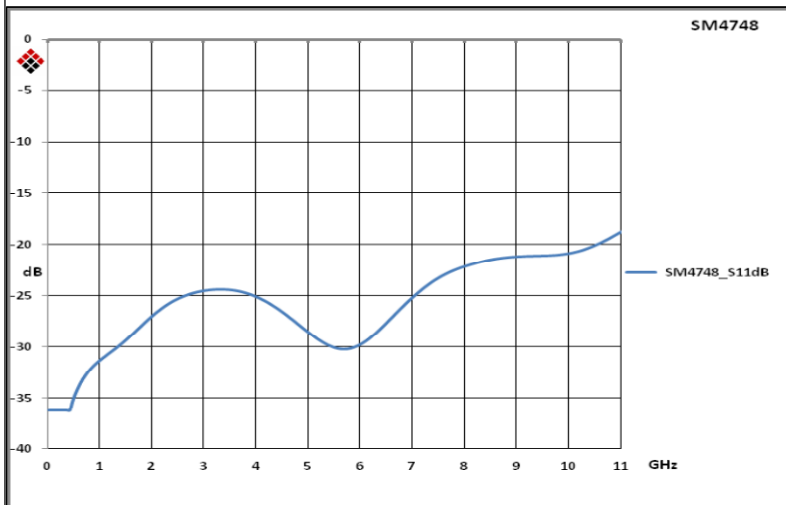

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M-TNC/F FLANGE 11GHZ ADAPTER

SIZE

A

CAGE CODE

3FKR5

DWG NO

SM4748

REV

A

SCALE

SHEET