

TNC ADAPTER 2GHZ COMMERCIAL GRADE

SM8720

SPECIFICATIONS

ELECTRICAL

FREQUENCY: 0-2 GHZ
IMPEDANCE: 50 OHMS
VSWR: 1.25:1 MAX 1GHZ
VSWR 1.75:1 MAX 2GHZ

MECHANICAL


MATERIALS BODY: NICKEL PLATED BRASS
MATERIALS CONTACTS BRASS
CONTACT PLATING: Au FLASH
INSULATOR: POM
INTERFACE: MIL-STD-348A

ROHS COMPLIANT

OP TEMP: -45-100° C


1.24"
(31.8)

TNC-M

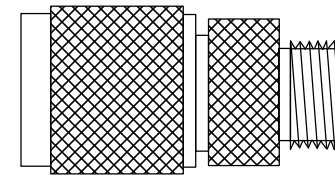

TNC-F

MEASUREMENTS BELOW ARE TYPICAL

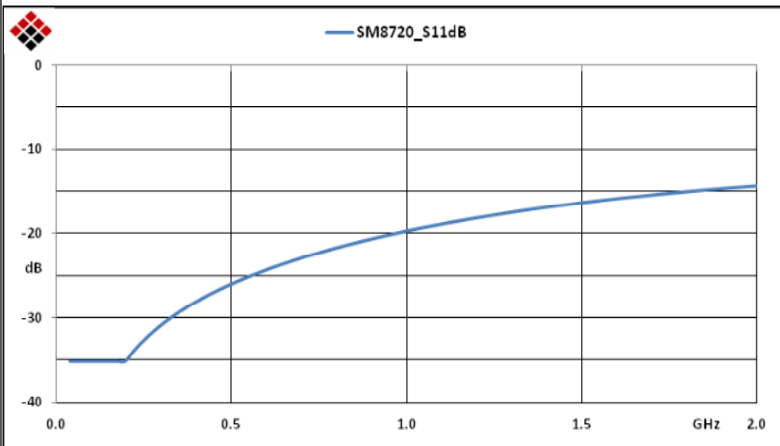

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**TNC ADAPTER 2GHZ
COMMERCIAL GRADE**

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SM8720	--

SCALE

SHEET