

MINISMP-M FD TERMINATION 40 GHZ

ST4086


SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 0-40 GHZ
IMPEDANCE: 50 OHMS
VSWR 1.20:1 @ 18 GHZ
VSWR 1.50:1 @ 40 GHZ
IMPEDANCE: 50 OHMS

MECHANICAL:

MATERIAL BODY: BeCu
CENTER CONTACTS: BeCu
PLATING: Au PER MIL-G-45204
OP. TEMP RANGE: -55° to +125°C
ROHS COMPLIANT

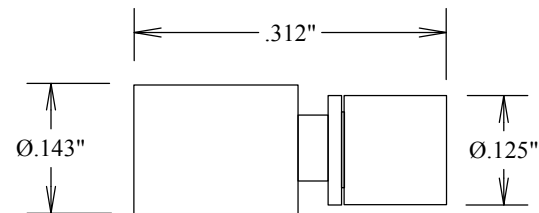

MINISMP-M
FULL DETENTE

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

MINISMP-M FD TERMINATION 40 GHZ

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	ST4086	--

SCALE

SHEET