

# TERMINATION BNC/MALE 4 GHZ 5 WATTS

ST4B5W

## SPECIFICATIONS

### ELECTRICAL:


FREQUENCY: 0-4 GHZ  
VSWR: 1.25:1 MAX TO 4 GHZ  
POWER (AVG) 5 WATTS @ 25° C  
POWER DERATES LINEARLY TO 1 WATT @ 125° C  
IMPEDANCE: 50 OHMS

### MECHANICAL:


MATERIAL BODY: ALBALOY PLATED BRASS  
MATERIAL HEAT SHRINK: ANODYZED ALUMINUM(BLACK)  
MATERIAL CONTACT: Au PLATED BRASS

### ENVIRONMENTAL:

TEMP: -40° C TO +120° C

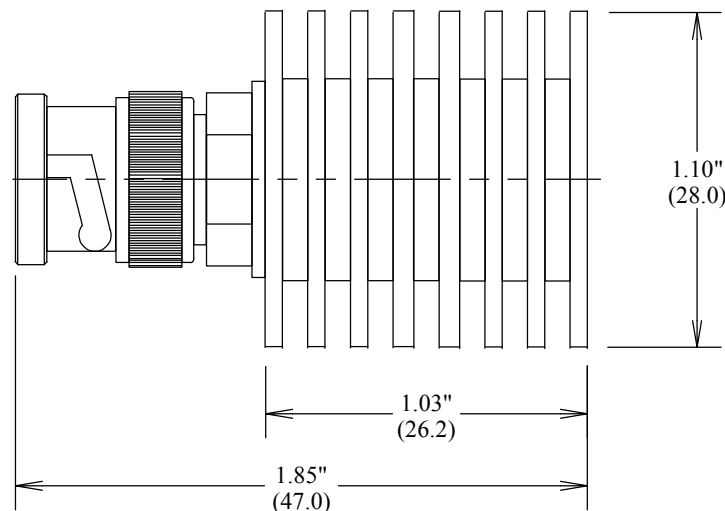

### MEASUREMENTS BELOW ARE TYPICAL

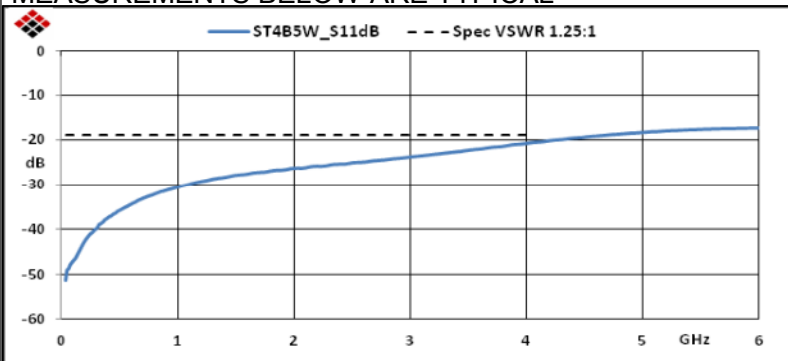

ALL DIMENSIONS IN inches(MM) Typical

## FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

### TERMINATION BNC/MALE 4 GHZ 5 WATTS

SIZE CAGE CODE DWG NO

A

3FKR5

ST4B5W

REV

A

SCALE

SHEET